


Item no.: 231-172/001-000
 Product description: HEADER; STRAIGHT SOLDER PIN, 1.2 X 1.2 MM /0.047 X 0.047 IN; 12 POLE; PIN SPACING 5 MM / 0.197 IN; MATING DIRECTION PERPENDICULAR TO PCB; WITH CLOSED END

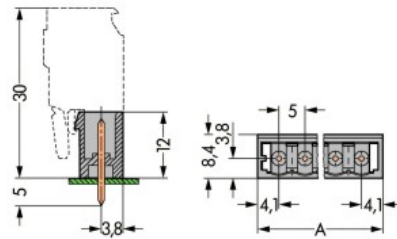

Packing unit 100 4*25 pieces

Product group	3 (Multi Conn. System)
Pin spacing from	5 mm
Pin spacing from	0,197 in
pole count	12
Measured voltage EN	250 V
Measured shock voltage	4 kV
Pollution degree	3
Current intensity EN	16 A
Weight	4,806 g
Color	grey
Height	12 mm
Height	0,472 in
Width	63,2 mm
Width	2,488 in
Depth	8,4 mm
Depth	0,331 in



Item number	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
231-172/001-000	ABS	04-HG469925-PDA	400	16	5,0
231-172/001-000	BV	11915/A0	400	16	2,5
231-172/001-000	CCA	5764	250	16	1,2x1,2
231-172/001-000	CSA	154112-1466354	300	15	
231-172/001-000	DEMKO	88126	250	16	2,5
231-172/001-000	GL	17296-00HH	400	16	5,0
231-172/001-000	KEMA	2083746.02	250	16	1,2x1,2
231-172/001-000	KR	HMB05880-EL003	250/400	12/16	2,5
231-172/001-000	LR	96/20035	400	16	5,0
231-172/001-000	NEMKO	P94101840	250		2,5
231-172/001-000	RMR	11130002	400	16	5,0
231-172/001-000	UR	E45171	600	15	
231-172/001-000	UR	E45172	300	15	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected