


## Data sheet




---

|                      |   |
|----------------------|---|
| Item no.:            | 231-380/001-000   |
| Product description: | HEADER; STRAIGHT SOLDER PIN, 1.2 X 1.2 MM / 0.047 X 0.047 IN; 20 POLE; PIN SPACING 5.08 MM / 0.2 IN; MATING DIRECTION PERPENDICULAR TO PCB; WITH CLOSED END |

---

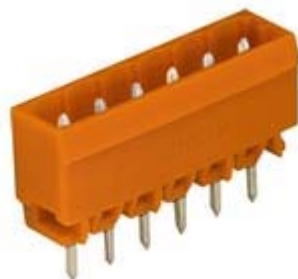

Packing unit 50 5\*10 pieces

|                        |          |
|------------------------|----------|
| Pin spacing from       | 5,08 mm  |
| Pin spacing from       | 0,2 in   |
| pole count             | 20       |
| Voltage CSA            | 300 V    |
| Voltage UL             | 300 V    |
| Current UL             | 15 A     |
| Current CSA            | 15 A     |
| Measured voltage EN    | 250 V    |
| Measured shock voltage | 4 kV     |
| Pollution degree       | 3        |
| Current intensity EN   | 16 A     |
| Weight                 | 7,92 g   |
| Color                  | orange   |
| Height                 | 12 mm    |
| Height                 | 0,472 in |
| Width                  | 104,8 mm |
| Width                  | 4,126 in |
| Depth                  | 8,4 mm   |
| Depth                  | 0,331 in |

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected