


Item no.: 232-124/026-000
 Product description: ANGLED FEMALE PLUG; 24 POLE; PIN SPACING 5 MM / 0.197 IN; WITH CODIG FINGERS; WITH INTEGRATED FIXING FLANGES; CONDUCTOR EXIT OPPOSITE TO LATCHES

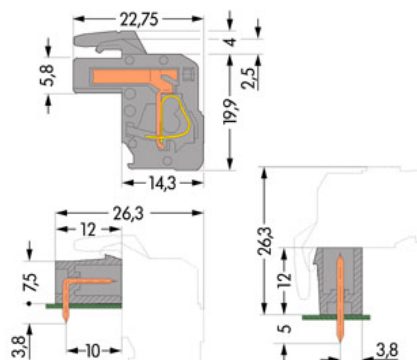

Packing unit 10 pieces

Product group	3 (Multi Conn. System)
Pin spacing from	5 mm
Pin spacing from	0,197 in
pole count	24
Cross section from [mm ²]	0,08 mm ²
Cross section to [mm ²]	2,5 mm ²
Cross section from [AWG]	28 AWG
Cross section to [AWG]	12 AWG
Connection method	CAGE CLAMP®CONNECTION
Measured voltage EN	250 V
Measured shock voltage	4 kV
Pollution degree	3
Current intensity EN	14 A
Weight	44,656 g
Color	grey
No. of connection Points	24
No. of potentials	24
Height	23,9 mm
Height	0,941 in
Width	122,4 mm
Width	4,819 in
Depth	22,75 mm



Depth	0,896 in
Strip length from	8 mm
Strip length to	9 mm
Strip length	0,33 in



Item number	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
232-124/026-000	ABS	04-HG469925-PDA	250	14	0,8-2,5
232-124/026-000	BV	11915/A0	400	16	2,5
232-124/026-000	CCA	5764	250	12	0,08-2,5
232-124/026-000	CSA	154112-1466354	300	15	22-12
232-124/026-000	DEMKO	88126	250		2,5
232-124/026-000	GL	17296-00HH	250	14	0,8-2,5
232-124/026-000	KEMA	2083746.02	250	12	0,08-2,5
232-124/026-000	KR	HMB05880-EL003	250/400	12/16	2,5
232-124/026-000	LR	96/20035	250	14	0,8-2,5
232-124/026-000	NEMKO	P94101840	250		2,5
232-124/026-000	RMR	11130002	250	14	0,8-2,5
232-124/026-000	UR	E45171	600	15	12
232-124/026-000	UR	E45172	300	15	22-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected