


Item no.: 236-401
 Product description: MODULAR PCB TERMINAL BLOCK; 2 SOLDER PINS / POLE; 1 POLE; PIN SPACING 5/5.08 MM / 0.2 IN; FRONT-/SIDE-ENTRY; CAGE CLAMP®CONNECTION



Packing unit 600 6*100 pieces

Product group	4 (Printed Circuit)
Pin spacing from	5 mm
Pin spacing up to	5,08 mm
Pin spacing from	0,197 in
Pin spacing up to	0,2 in
pole count	1
Cross section from [mm²]	0,08 mm²
Cross section to [mm²]	2,5 mm²
Cross section from [AWG]	28 AWG
Cross section to [AWG]	12 AWG
Connection method	CAGE CLAMP®CONNECTION
Measured voltage EN	250 V
Measured shock voltage	4 kV
Pollution degree	3
Current intensity EN	16 A
Measured voltage EN	500 V
Measured shock voltage	4 kV
Pollution degree	2
Current intensity EN	16 A
Weight	0,877 g
Color	grey
Wiring type	Front-/Side-entry

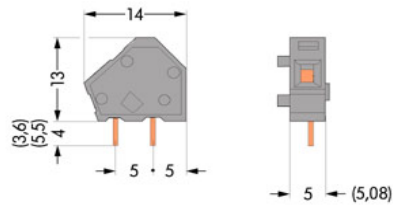

No. of connection Points	1
No. of potentials	1
Height	13 mm
Height	0,512 in
Width	5 mm
Width	0,197 in
Depth	14 mm
Depth	0,551 in
Strip length from	5 mm
Strip length to	6 mm
Strip length	0,22 in



Item number	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
236-401	BV	11915/BO	500/250	16	0,08-2,5
236-401	CCA	NL6247	250	24	0,08-2,5
236-401	CSA	154112-1673957	300	15	28-12
236-401	DNV	E7569	250	16	0,5-2,5
236-401	GL	17296-00HH	500/250	16	0,5-2,5
236-401	KEMA	2110204.01	250	24	0,08-2,5
236-401	NEMKO	M58459/01	50		2,5
236-401	RMR	11130002	250	16	0,5-2,5
236-401	SEMKO	9411003	400		2,5
236-401	UR	E45172	300	15	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected