


Item no.: 237-136
 Product description: MODULAR TERMINAL BLOCK; WITH WIRE PROTECTION; 6 POLE; PIN SPACING 5 MM / 0.197 IN; SCREW CLAMP CONNECTION

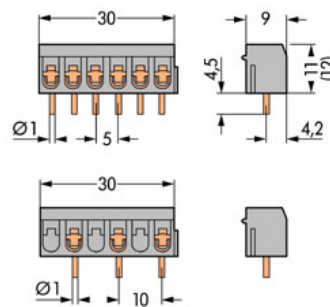

Packing unit 300 3*100 pieces

Product group	4 (Printed Circuit)
Pin spacing from	5 mm
Pin spacing from	0,197 in
pole count	6
Cross section from [mm ²]	0,5 mm ²
Cross section to [mm ²]	2,5 mm ²
Cross section from [AWG]	20 AWG
Cross section to [AWG]	14 AWG
Connection method	SCREW CONNECTION
Measured voltage EN	250 V
Measured shock voltage	2,5 kV
Pollution degree	2
Current intensity EN	16 A
Weight	5,716 g
Color	grey
Wiring type	Side-entry
No. of connection Points	6
No. of potentials	6
Height	11 mm
Height	0,433 in
Width	5 mm
Width	0,197 in



Depth	9 mm
Depth	0,354 in
Strip length from	5 mm
Strip length to	7 mm
Strip length	0,24 in



Item number	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
237-136	CBcertificateINDIEN	98-02629	250	16	0,5-2,5
237-136	CCA	NL6290	250	24	0,5-2,5
237-136	CSA	18677-6	300	10	20-14
237-136	KEMA	110204.13	250	24	0,5-2,5
237-136	RMR	11130002	250	16	0,5-2,5
237-136	UR	E45172	150	10	18-14

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected