


Item no.: 262-334
 Product description: 4-CONDUCTOR TERMINAL BLOCK; LATERAL MARKING;
 SUITABLE FOR EX I APPLICATIONS; WITH FIXING
 FLANGE; WITH MOUNTING FEET 209-123 FOR TS 35; SIDE-
 ENTRY

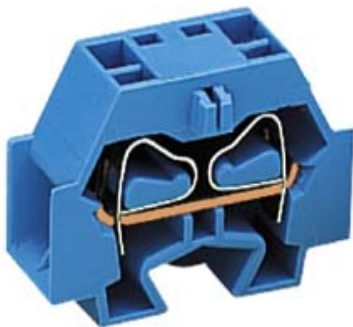

Packing unit 100 2*50 pieces

Product group	9 (Std Chassis Mt Blocks)
Cross section from [mm ²]	0,08 mm ²
Cross section to [mm ²]	4 mm ²
Cross section from [AWG]	28 AWG
Cross section to [AWG]	12 AWG
Connection method	CAGE CLAMP®CONNECTION
Measured voltage EN	630 V
Measured shock voltage	8 kV
Pollution degree	3
Current intensity EN	32 A
Weight	6,82 g
Color	blue
Wiring type	Side-entry
No. of connection Points	4
No. of potentials	1
Height	23 mm
Height	0,906 in
Width	12 mm
Width	0,472 in
Depth	33,5 mm
Depth	1,32 in
Strip length from	9 mm
Strip length to	10 mm
Strip length	0,37 in



Item number	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
262-334	ABS	04-HG476174-PDA	630	32	4
262-334	BV	07436/C0			0,08-4
262-334	CCA	NL5802	630		0,08-4
262-334	CCA	TE/1718/880590/08	630		0,08-4
262-334	CSA	18677-45	300/600	20/5	26-12
262-334	DNV	E7569	630	32	4
262-334	GL	17295-00HH	630	32	4
262-334	KEMA	2079569.03	630		0,08-4
262-334	KR	HMB05880-EL002	630	32	32
262-334	LR	92/20242(E5)	630	24	4
262-334	RMR	11130002	630	32	4
262-334	UR	E45172	300/600	20/5	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected