


Item no.: 284-621  
 Product description: DISTRIBUTION TERMINAL BLOCK; 3 x CAGE CLAMP® connection 10 mm<sup>2</sup>; 1 x SCREW-CLAMP CONNECTION 35 MM<sup>2</sup>/AWG 2; LATERAL MARKING; for DIN 35 rail; FRONT-/SIDE-ENTRY

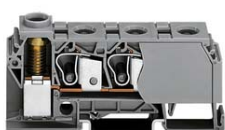

Packing unit 15 pieces

Product group	1 (Rail Mounted Terminal Blocks)
Cross section from [mm <sup>2</sup> ]	0,2 mm <sup>2</sup>
Cross section to [mm <sup>2</sup> ]	10 mm <sup>2</sup>
Cross section from [AWG]	24 AWG
Cross section to [AWG]	8 AWG
Connection method	CAGE CLAMP®CONNECTION
Number of strands	73
Cross section from [mm <sup>2</sup> ]	6 mm <sup>2</sup>
Cross section to [mm <sup>2</sup> ]	35 mm <sup>2</sup>
Cross section from [AWG]	10 AWG
Cross section to [AWG]	2 AWG
Measured voltage EN	800 V
Measured shock voltage	8 kV
Pollution degree	3
Current intensity EN	125 A
Weight	55,5 g
Color	grey
Wiring type	Front-/Side-entry
No. of connection Points	4
No. of potentials	1
Height	39,5 mm
Height	1,55 in



Width	0,689 in
Depth	89 mm
Depth	3,507 in
Strip length from	12 mm
Strip length to	14 mm
Strip length	0,51 in



Item number	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
284-621	ABS	05-HG476175/1-PDA	500	125	35
284-621	BV	07436/C0			0,2-10
284-621	CB-certificateChina	NL10208	800	125	35
284-621	CCA	NL5910	800		35
284-621	CSA	154112-1536073	600	110	1x10-2/3x24-8
284-621	DNV	E7570	500	125	35
284-621	GL	17295-00HH	500	125	35
284-621	KEMA	2082859.11	800	125	35
284-621	LR	91/20112(E5)	500	125	35
284-621	PRS	TE/1718/880590/08	800		35
284-621	RMR	11130002	500	125	35
284-621	UL	E45172	600	115	24-8
284-621	UR	E45172	600	115	24-8

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected