


Item no.: 286-426
 Product description: SWITCHING RELAY MODULE IMPULSE PROLONGING WITH HELP VOLTAGE WITH TRIGGER VOLTAGE RELAY WITH 1 CHANGEVER CONTACT (1u)

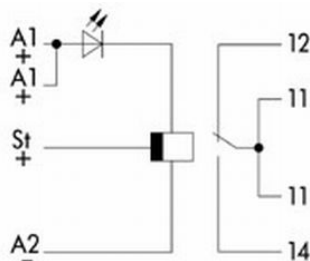

Produkt kann von Bild abweichen / product may differ

Packing unit 10 10*1 pieces

RoHS compliant

Product group	6 (Electronics)
Time range	0.1 - 1 s
Input voltage	DC 24 V
Contact material	AgCdO, with gold flash
max. switching voltage	DC 250V / AC 380V
max. make current	1 s 15 A
max. break current	8 A
max. continuous current	6 A
max. switching power (resistive) VA	2000 VA
max. switching power (resistive) W	150 W
Operating power	360 mW
Pull-in time (typ)	10 ms
Bounce time (typ)	1 ms
Trigger voltage	DC 24 V
Reset time	100 ms
Dielectric strength contact-coil (AC, 1 min)	3 kV
Nominal voltage acc. to VDE 0110/1.89	250 V / 4 kV / 3
Mechanical life	5 x 10 ⁷ switching operations

Mechanical life at max. resistive load AC	1 x 10 ⁵ switching operations
Ambient operating temperature	-25 °C ... +40 °C
Current consumption at UN (20 °C)	15 mA
Weight	33.6 g
Color	gray

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected