


Item no.: 51018351  
 Product description: Relay module Relay with 1 make contact (1a)

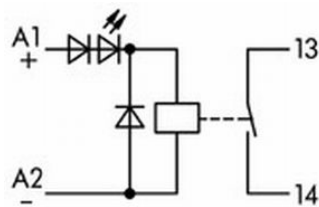

Produkt kann von Bild abweichen / product may differ

Packing unit 1 piece

RoHS compliant

Product group	6 (Electronics)
Coil voltage DC	48 V
max. switching voltage	AC 250 V / DC 30 V
max. make current	5 A
max. break current	5 A
max. continuous current	5 A
max. switching power (resistive) VA	1250 VA
max. switching power (resistive) W	150 W
Pull-in power	100 mW
Operating power	200 mW
Pull-in time (typ)	6 ms
Drop-out time (typ)	6 ms
Bounce time typ	2 ms
Dielectric strength contact-coil (AC, 1 min)	2.5 kV
Nominal voltage acc. to VDE 0110/1.89	Safety data
Mechanical life	2 x 10 <sup>7</sup> switching operations
Mechanical life at max. resistive load AC	1 x 10 <sup>5</sup> switching operations
Ambient operating temperature	-25 °C ... +40 °C
Current consumption at UN (20 °C)	8.6 mA

Weight	15.7 g
Color	grey
Customs Tariff No.	85369010
Country of Origin	Deutschland

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected