


Item no.: 733-204
 Product description: MALE CONNECTOR 4 POLE PIN SPACING 2.5 MM / 0.098 IN
 100% PROTECTED AGAINST MISMATING

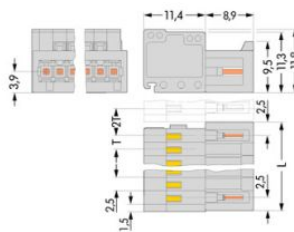

Produkt kann von Bild abweichen / product may differ

Packing unit 200 pieces

RoHS compliant

| | |
|--------------------------|------------|
| Weight | 2.17 g |
| Color | light gray |
| No. of connection Points | 4 |
| No. of potentials | 4 |
| pole count | 4 |
| Height | 11.8 mm |
| Height | 0.465 in |
| Width | 12.5 mm |
| Width | 0.492 in |
| Depth | 20.3 mm |
| Depth | 0.799 in |
| Pin spacing from | 2.5 mm |
| Pin spacing from | 0.098 in |
| Pollution degree | 2 |
| Measured voltage EN | 160 V |
| Measured shock voltage | 2.5 kV |
| Current intensity EN | 6 A |
| Pollution degree | 2 |
| Measured voltage EN | 320 V |

Measured shock voltage
Current intensity EN
Connection method

2.5 kV
6 A
CAGE CLAMP® CONNECTION



| | |
|----------------------------------|--|
| Cross section [mm ²] | 0.08 - 0.5 mm ² |
| Wiring method | solid |
| Cross section [mm ²] | 0.08 - 0.5 mm ² |
| Wiring method | fine-stranded |
| Cross section [mm ²] | 0.25 - 0.34 mm ² |
| Wiring method | fine-stranded (with ferrule and plastic collar) |
| Cross section [mm ²] | 0.25 - 0.34 mm ² |
| Wiring method | fine-stranded (with ferrule, without plastic collar) |
| Cross section [AWG] | 28 - 20 AWG |
| Strip length from | 5 mm |
| Strip length to | 6 mm |
| Material group | I |
| Contact material | Electrolytic copper (Ecu) |
| Contact surface | tin-plated |
| xxx-xxx/032-000 | Strain relief plate 6 mm |



| Item no. | Admission office | Approval no. | Voltage [V] | Current [A] | Cross section [mm ²] |
|----------|------------------|-------------------|-------------|-------------|-----------------------------------|
| 733-204 | ABS | 04-HG469925/1-PDA | 250 | 4 | 0,08-0,5 |
| 733-204 | BV | 11915/A0 | 250 | 4 | 0,08-0,5 |
| 733-204 | CCA | NL5640 | 250 | 4 | 0,08-0,5 |
| 733-204 | CSA | 154112-1465035 | 150 | 4 | 28-20 |
| 733-204 | DNV | E-9218 | 250 | 4 | 0,08-0,5 |
| 733-204 | GL | 17296-00HH | 250 | 4 | 0,08-0,5 |
| 733-204 | KEMA | 2077592.01 | 250 | 4 | 0,08-0,5 |
| 733-204 | LR | 96/20035 | 250 | 6 | 0,08-0,5 |
| 733-204 | RMR | 11130002 | 250 | 4 | 0,08-0,5 |
| 733-204 | UR | E45171 | 250 | 4 | 28-20 |
| 733-204 | UR | E45172 | 150 | 4 | 28-20 |

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected