


Item no.: 733-338  
 Product description: HEADER STRAIGHT SOLDER PIN 0.8x0.8 MM 8 POLE PIN SPACING 2.5 MM / 0.098 IN 100% PROTECTED AGAINST MISMATING MATING DIRECTION PERPENDICULAR TO PCB WITH CLOSED END

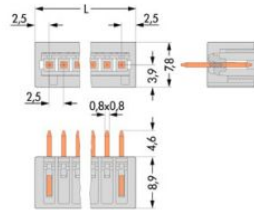

Produkt kann von Bild abweichen / product may differ

Packing unit 200 pieces

RoHS compliant

Weight	1.173 g
Color	light gray
pole count	8
Height	8.9 mm
Height	0.35 in
Width	22.5 mm
Width	0.886 in
Depth	7.8 mm
Depth	0.307 in
Pin spacing from	2.5 mm
Pin spacing from	0.098 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV
Current intensity EN	6 A
Pollution degree	2
Measured voltage EN	320 V

Measured shock voltage	2.5 kV
Current intensity EN	6 A
Material group	I
Contact material	Electrolytic copper (Ecu)
Contact surface	tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
733-338	ABS	04-HG469925/1-PDA	250	4	
733-338	BV	11915/A0	250	4	
733-338	CCA	NL5640	250	4	
733-338	CSA	154112-1465035	150	4	28-20
733-338	DNV	E-9218	250	4	
733-338	GL	17296-00HH	250	4	
733-338	KEMA	2077592.01	250	4	
733-338	LR	96/20035	250	6	
733-338	RMR	11130002	250	4	
733-338	UR	E45171	250	4	
733-338	UR	E45172	150	4	28-20

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected