


Item no.: 734-162
 Product description: HEADER RIGHT ANGLE SOLDER PIN, 1 X 1 MM / 0.039 X 0.039 IN 2 POLE PIN SPACING 3.5 MM / 0.138 IN 100% PROTECTED AGAINST MISMATING WITH CLOSED END MATING DIRECTION PARALLEL TO PCB

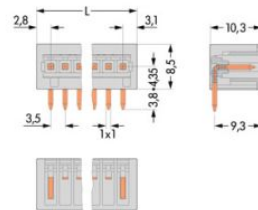

Produkt kann von Bild abweichen / product may differ

Packing unit 200 pieces

RoHS compliant

Product group	3 (Multi Conn. System)
Weight	0.648 g
Color	light gray
pole count	2
Height	8.5 mm
Height	0.335 in
Width	9.4 mm
Width	0.37 in
Depth	10.3 mm
Depth	0.406 in
Pin spacing from	3.5 mm
Pin spacing from	0.138 in
Pollution degree	2
Measured voltage EN	160 V
Measured shock voltage	2.5 kV
Current intensity EN	10 A
Pollution degree	2

Measured voltage EN	320 V
Measured shock voltage	2.5 kV
Current intensity EN	10 A
Material group	I
Contact material	Electrolytic copper (Ecu)
Contact surface	tin-plated



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
734-162	ABS	04-HG469925/1-PDA	250	10	0,5-1,5
734-162	BV	11915/A0	250	10	0,5-1,5
734-162	CCA	NL5641	250	10	0,5-1,5
734-162	CSA	154112-1465035	300	10	28-14
734-162	DNV	E-9218	250	10	0,5-1,5
734-162	GL	17296-00HH	250	10	0,5-1,5
734-162	KEMA	2077592.02	250	10	0,5-1,5
734-162	LR	96/20035	250	10	0,5-1,5
734-162	RMR	11130002	250	10	0,5-1,5
734-162	UR	E45171	250	10	28-14
734-162	UR	E45172	300	10	

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected