

Item description

- Only for use with cable binders
- Cable binder width: max. 3.6 mm
- 1 x cable outlet, rear

Data

Connection data

Pole No.	4
----------	---

Physical data

Pin spacing	3.5 mm / 0.138 inch
Width	17 mm / 0.669 inch
Height	14.4 mm / 0.567 inch
Depth	32.7 mm / 1.287 inch

Subject to changes. Please also observe the further product documentation!

Mechanical data

Suitable for standard male and female connectors

Material data


Color	light gray
Fire load	0.079 MJ
Weight	2.6 g

Commercial data



Product Group	3 (Multi Conn. System)
Packaging type	BOX
Country of origin	DE
GTIN	4017332548199
Customs tariff number	39269097900

Approvals / Certificates

Country specific Approvals

Logo	Approval	Additional Approval Text	Certificate name
	CCA DEKRA Certification B.V.	EN 61984	2169534.02
	CCA DEKRA Certification B.V.	EN 61984	nl-54190

Ship Approvals

Logo	Approval	Additional Approval Text	Certificate name
	ABS American Bureau of Shipping	-	19- HG1869876- PDA
	DNV GL Det Norske Veritas, Germanischer Lloyd	-	TAE000016Z
	LR Lloyds Register	IEC 61984	96/20035 (E5)

Subject to changes. Please also observe the further product documentation!



Downloads

Documentation

Additional Information

Technical explanations	2019 Apr 3	pdf 2.0 MB	Download
------------------------	------------	---------------	----------

CAD/CAE-Data

CAD data

2D/3D Models 734-604	URL	Download
----------------------	-----	----------

CAE data

ZUKEN Portal 734-604	URL	Download
----------------------	-----	----------

EPLAN Data Portal 734-604	URL	Download
---------------------------	-----	----------

Environmental Product Compliance


Compliance Search

Environmental Product Compliance 734-604 Strain relief housing; light gray	URL	Download
---	-----	----------

Installation Notes


Application

Subject to changes. Please also observe the further product documentation!

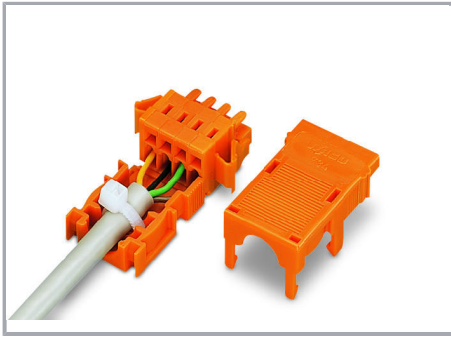

4-pole, 1-conductor female connector, with locking levers and strain relief housing (2- to 5-pole strain relief housing suitable only for cable ties)

Application

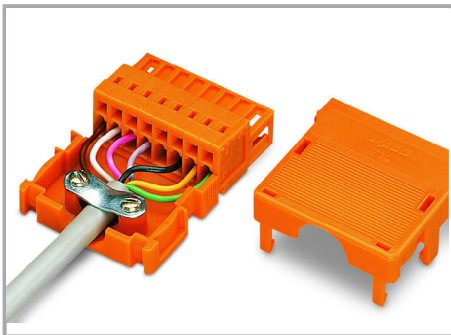

Strain relief housing for 734 Series Male and Female Connectors with CAGE CLAMP® connection

Subject to changes. Please also observe the further product documentation!