


Item no.: 770-113  
 Product description: PLUG WITH RELIEF HOUSING 3 POLE PIN SPACING 10 MM / 0.394 IN 100% PROTECTED AGAINST MISMATING WIRE DIAMETER 8-12 MM

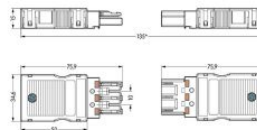

Produkt kann von Bild abweichen / product may differ

Packing unit 25 pieces

RoHS compliant

Product group	20 (WINSTA)
pole count	3
Cross section [mm <sup>2</sup> ]	0.5 - 4 mm <sup>2</sup>
Cross section [AWG]	20 - 12 AWG
Connection method	CAGE CLAMP®S Connection
Number of strands	2
Measured voltage EN	250 V
Measured shock voltage	4 kV
Pollution degree	3
Current intensity EN	25 A
Weight	19.435 g
Color	black
No. of connection Points	6
No. of potentials	3
Height	15 mm
Height	0.591 in
Width	34.6 mm
Width	1.362 in

Depth	75.9 mm
Depth	2.988 in
Strip length from	9 mm
Strip length to	9 mm
Strip length	0.35 in



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
770-113	ABS	06-HG154986/11-PDA	250	25	0,5-4,0
770-113	CBCertificateVDE	DE1-29543	250/400	25	0,5-4
770-113	CCA		250	25	0,5-4,0
770-113	cURus	E45171	600	20	12
770-113	DNV	E-9217	250	25	4
770-113	GL	42875-02HH	250	25	4
770-113	KEMA		250	25	0,5-4,0
770-113	LR	02/20050(E3)	250	25	2,5
770-113	PRS	TE/1719/880590/08	250	25	0,5-4,0
770-113	PSE	JET0695-43009-1001	600	20	12
770-113	VDE	Ausweis.Nr.30726	250/400	16/25	0,5-4,0

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected