



Data sheet | Item number: 811-316

2-conductor fuse terminal block; for cylindrical fuses 10 x 38 mm; 13/32" x 11/2"; for photovoltaic applications; without blown fuse indication; for DIN-rail 35 x 15 and 35 x 7.5; 16 mm²; CAGE CLAMP®; 16,00 mm²; light gray

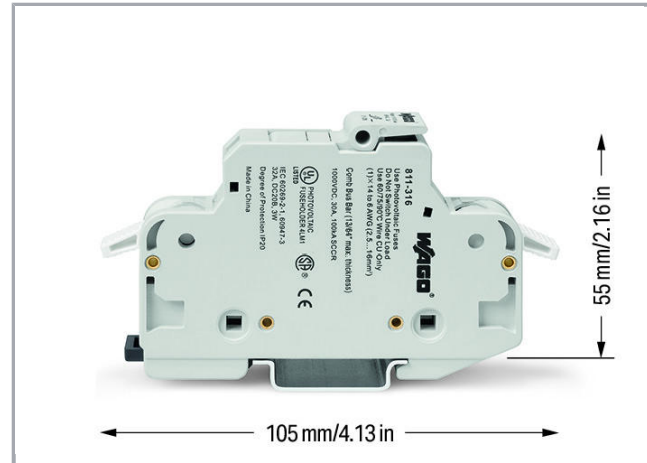

www.wago.com/811-316

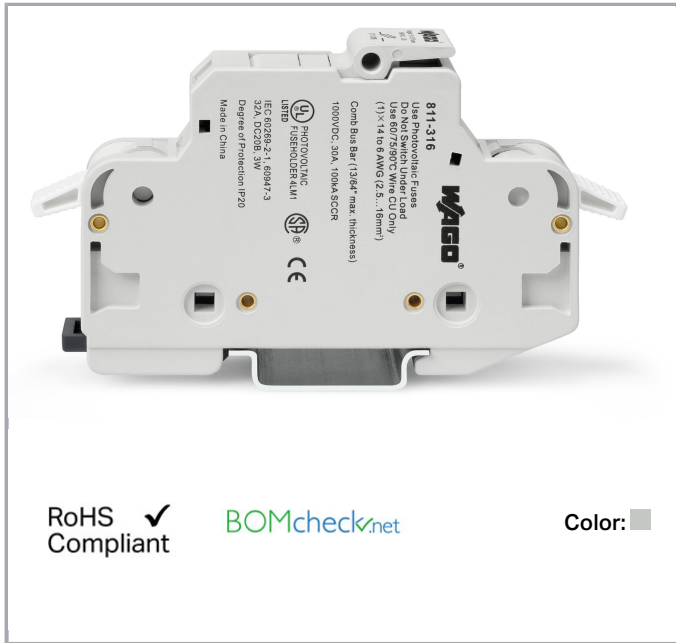

RoHS
Compliant ✓

BOMcheck.net

Color: ■

Item description

Safety information 1:

Electrical ratings are given by the fuse.

Safety information 2:

Temperature range handling from -35°C ... +85°C

Data

Electrical data

Voltage type (1)	DC
------------------	----

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	1000 V
Rated current	32 A

Connection data

Connection technology	CAGE CLAMP®
-----------------------	-------------

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG
Hansastr. 27
32423 Minden
Phone: +49571 887-0 | Fax: +49571 887-169
Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?
We are always happy to take your call at +49 (571) 887-44222.



Actuation type	Operating tool
Connectable conductor materials	Copper
Solid conductor	2.5 ... 16 mm ² / 14 ... 6 AWG
Fine-stranded conductor	2.5 ... 16 mm ² / 16 ... 6 AWG
Strip length	12 ... 13 mm / 0.47 ... 0.51 inch
No. of poles	1
Total number of connection points	2
Total number of potentials	1
Number of levels	1
Type of wiring	Side-entry wiring

Geometrical Data

Width	17.5 mm / 0.689 inch
Height from upper-edge of DIN-35 rail	55 mm / 2.165 inch
Depth	105 mm / 4.134 inch

Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail

Material Data

Color	light gray
Insulating material	Polyamide 66 (PA 66)
Weight	63.1 g

Commercial data

Packaging type	BOX
Country of origin	CN
GTIN	4050821849001
Customs Tariff No.	85369095990

Compatible products

assembling

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG
 Hansastr. 27
 32423 Minden
 Phone: +49571 887-0 | Fax: +49571 887-169
 Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?
 We are always happy to take your call at +49 (571) 887-44222.



Item no.: 811-612
Coupling kit; for 12 poles

www.wago.com/811-612

Jumper



Item no.: 811-472
Push-in type jumper bar; insulated; 2-way; Nominal current 63 A; light gray

www.wago.com/811-472



Item no.: 811-473
Push-in type jumper bar; insulated; 3-way; Nominal current 63 A; light gray

www.wago.com/811-473



Item no.: 811-474
Push-in type jumper bar; insulated; 4-way; Nominal current 63 A; light gray

www.wago.com/811-474



Item no.: 811-475
Push-in type jumper bar; insulated; 5-way; Nominal current 63 A; light gray

www.wago.com/811-475



Item no.: 811-476
Push-in type jumper bar; insulated; 6-way; Nominal current 63 A; light gray

www.wago.com/811-476



Item no.: 811-477
Push-in type jumper bar; insulated; 7-way; Nominal current 63 A; light gray

www.wago.com/811-477



Item no.: 811-478
Push-in type jumper bar; insulated; 8-way; Nominal current 63 A; light gray

www.wago.com/811-478



Item no.: 811-479
Push-in type jumper bar; insulated; 9-way; Nominal current 63 A; light gray

www.wago.com/811-479



Item no.: 811-480
Push-in type jumper bar; insulated; 10-way; Nominal current 63 A; light gray

www.wago.com/811-480



Item no.: 811-481
Push-in type jumper bar; insulated; 11-way; Nominal current 63 A; light gray

www.wago.com/811-481



Item no.: 811-482
Push-in type jumper bar; insulated; 12-way; Nominal current 63 A; light gray

www.wago.com/811-482

Marking accessories



Item no.: 285-442
Adaptor

www.wago.com/285-442



Item no.: 793-501
WMB marking card; as card; not stretchable; plain; snap-on type; white

www.wago.com/793-501



Item no.: 793-501/000-002
WMB marking card; as card; not stretchable; plain; snap-on type; yellow

www.wago.com/793-501/000-002



Item no.: 793-501/000-005
WMB marking card; as card; not stretchable; plain; snap-on type; red

www.wago.com/793-501/000-005

Subject to changes.



Item no.: 793-501/000-006
WMB marking card; as card; not stretchable; plain; snap-on type; blue

www.wago.com/793-501/000-006



Item no.: 793-501/000-007
WMB marking card; as card; not stretchable; plain; snap-on type; gray

www.wago.com/793-501/000-007



Item no.: 793-501/000-012
WMB marking card; as card; not stretchable; plain; snap-on type; orange

www.wago.com/793-501/000-012



Item no.: 793-501/000-017
WMB marking card; as card; not stretchable; plain; snap-on type; light green

www.wago.com/793-501/000-017



Item no.: 793-501/000-023
WMB marking card; as card; not stretchable; plain; snap-on type; green

www.wago.com/793-501/000-023



Item no.: 793-501/000-024
WMB marking card; as card; not stretchable; plain; snap-on type; violet

www.wago.com/793-501/000-024



Item no.: 793-5501
WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; white

www.wago.com/793-5501



Item no.: 793-5501/000-002
WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; yellow

www.wago.com/793-5501/000-002



Item no.: 793-5501/000-005
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; red

www.wago.com/793-5501/000-005



Item no.: 793-5501/000-006
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; blue

www.wago.com/793-5501/000-006



Item no.: 793-5501/000-007
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; gray

www.wago.com/793-5501/000-007



Item no.: 793-5501/000-012
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; orange

www.wago.com/793-5501/000-012



Item no.: 793-5501/000-014
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; brown

www.wago.com/793-5501/000-014

Subject to changes.



Item no.: 793-5501/000-017

WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; light green

www.wago.com/793-5501/000-017



Item no.: 793-5501/000-023

WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; green

www.wago.com/793-5501/000-023



Item no.: 793-5501/000-024

WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; violet

www.wago.com/793-5501/000-024

Supply module



Item no.: 811-471

Supply module; 35 mm²; for 811 Series Fuse Terminal Blocks; SCREW CLAMP CONNECTION; light gray

www.wago.com/811-471

Downloads

Documentation

Bid Text

811-316 X81 - Datei	Feb 19, 2019	xml 3.8 kB	Download
811-316 doc - Datei	Mar 14, 2017	doc 27.6 kB	Download

Additional Information

Technical explanations	Apr 3, 2019	pdf 2.1 MB	Download
------------------------	-------------	---------------	----------

CAD/CAE-Data

CAE data

EPLAN Data Portal 811-316	Download
WSCAD Universe 811-316	Download


Installation Notes

Assembly

Subject to changes.




Creating a 2- or 3-pole fuse terminal block via coupling kit.

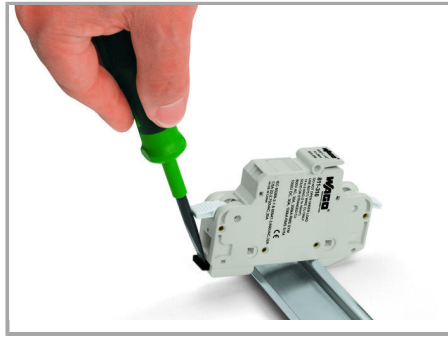


Removing a terminal block from the carrier rail.


Inserting a conductor

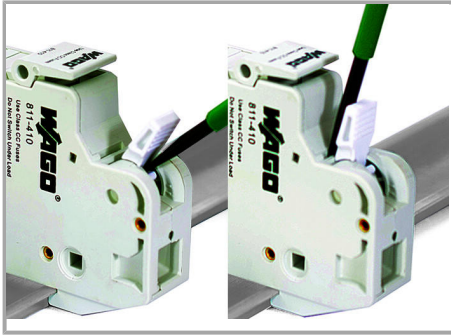

Opening/closing lever via screwdriver.

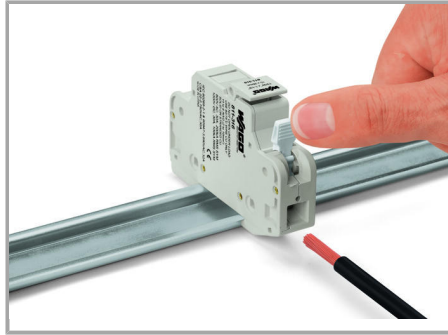

CAGE CLAMP® connection

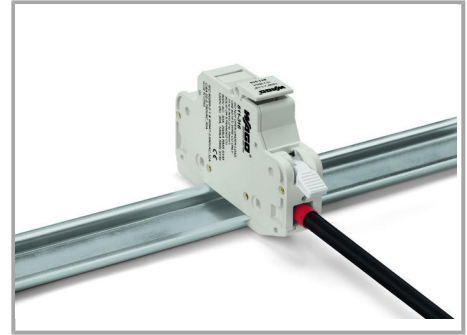


Terminating ferruled conductors up to 10 mm² (8 AWG).

Inserting a conductor via screwdriver.


Opening the clamping unit via integrated lever.

Jumpered

Subject to changes.

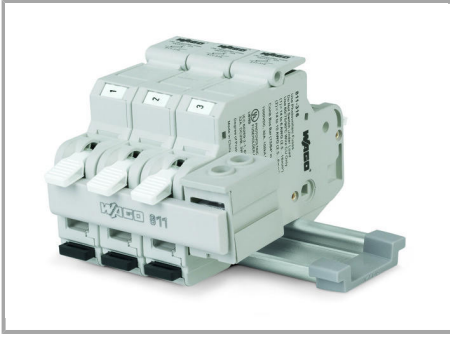


Jumper bar for quick and convenient commoning

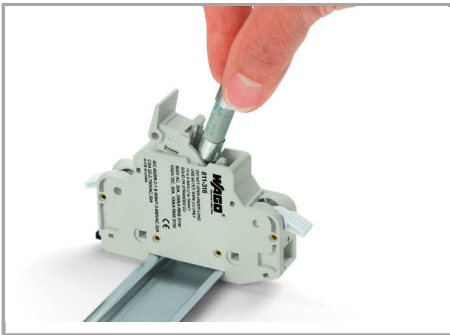


Inserting a fuse.

Marking

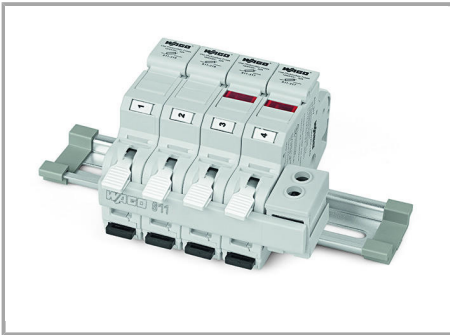

WMB marking location for convenient identification

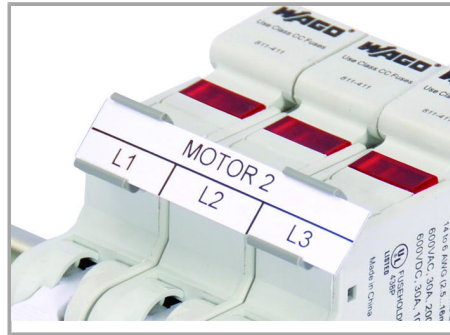

Marker carriers (285-442) for continuous marking strips

Subject to changes.