

Interface module; with male connector per DIN 41651; 26-pole

Item No.: 289-505



Interface module; with male connector per DIN 41651; 26-pole

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	289-505
EAN	4045454353483
Content	1
Order amount	1
Customer item number	

Notes

Technical data

<i>Miscellaneous</i>	
No. of Poles	26
Pollution degree (1)	2
Rated voltage EN (1) [V]	50 [V]
Rated surge voltage (1) [kV]	0.8 [kV]
Wire connection	WAGO 236 Series
Operating voltage	125 V AC / DC
Nominal current [A]	1 [A]
Connector contact	phosphor-bronze, 0.38 µm Au selectively over 1.3 µm Ni
Performance level	3
Connection technology (1)	CAGE CLAMP®

Technical data

<i>Cross section from (1) [mm²]</i>	<i>0.08 [mm²]</i>
<i>Cross section up to (1) [mm²]</i>	<i>2.5 [mm²]</i>
<i>Cross section from (1) [AWG]</i>	<i>28 [AWG]</i>
<i>Cross section up to (1) [AWG]</i>	<i>12 [AWG]</i>
<i>Stripped length from (1) [mm]</i>	<i>5 [mm]</i>
<i>Stripped length up to (1) [mm]</i>	<i>6 [mm]</i>
<i>Stripped length (1) [in]</i>	<i>0.22 [in]</i>
<i>Weight [g]</i>	<i>76 [g]</i>
<i>Width [mm]</i>	<i>71 [mm]</i>
<i>Width [in]</i>	<i>2.795 [in]</i>
<i>Height [mm]</i>	<i>36 [mm]</i>
<i>Height [in]</i>	<i>1.417 [in]</i>
<i>Length [mm]</i>	<i>85 [mm]</i>
<i>Length [in]</i>	<i>3.346 [in]</i>
<i>Type of mounting</i>	<i>DIN 35 rail</i>

Accessories

Accessories



Carrier rail

Item no.	Description	Pack. unit (Sub Pack)
210-112	Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to en 60715; "Hole width 25 mm	1
210-113	Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to en 60715	1
210-114	Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; according to en 60715	1
210-115	Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to en 60715; "Hole width 18 mm	1
210-118	Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to en 60715	1
210-196	Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; according to en 60715	1
210-197	Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; according to en 60715	1
210-198	Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to en 60715	1
210-504	Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715	1
210-505	Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715	1
210-506	Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; ähnlich EN 60715	1
210-508	Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; ähnlich EN 60715	1

General accessory

Item no.	Description	Pack. unit (Sub Pack)
210-657	Operating tool with partially insulated shaft; blade (3.5 x 0.5) mm; short; suitable for 260, 261, 262, 264, 270, 280, 281, 869, 870 and 880 Series	1

Images & drawings

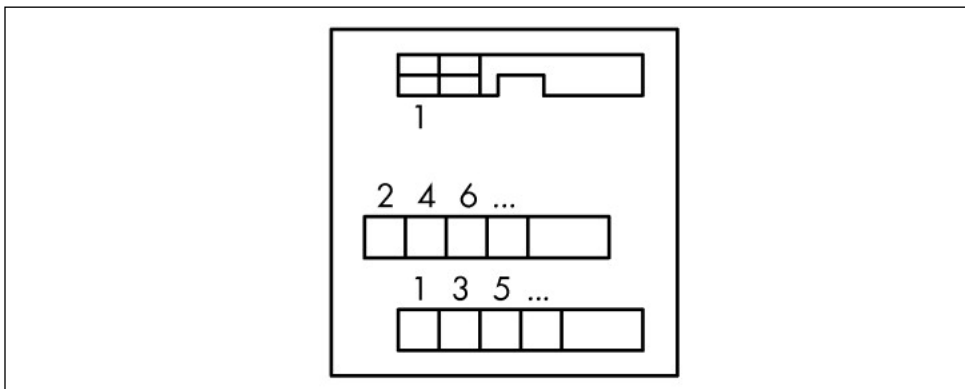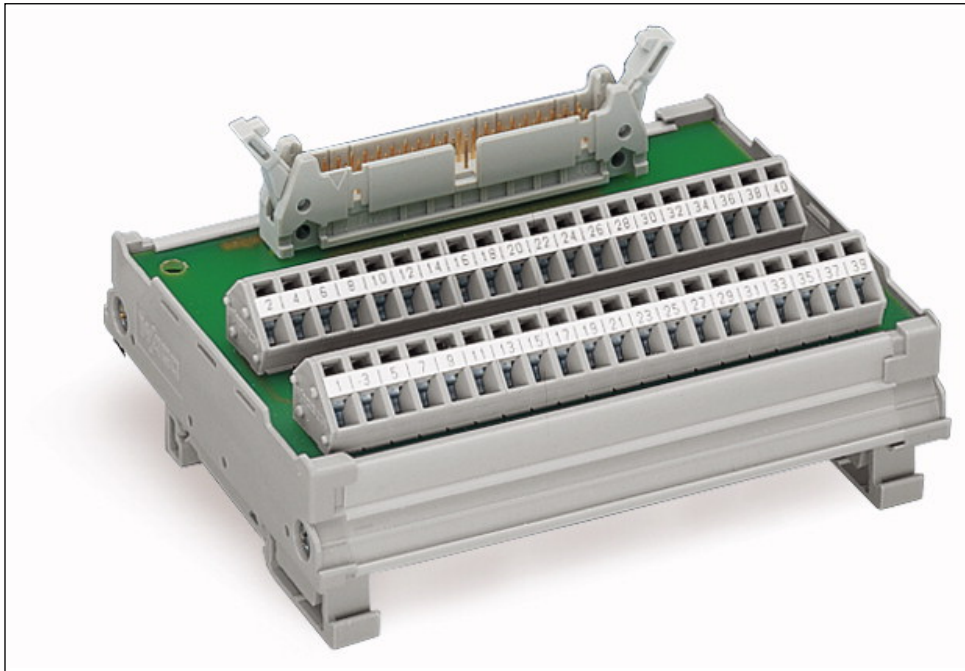

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.