


Item no.: 721-603  
 Product description: MALE CONNECTOR 3 POLE PIN SPACING 5 MM / 0.197 IN  
 100% PROTECTED AGAINST MISMATING WITHOUT  
 PRECEDING GROUND CONTACT

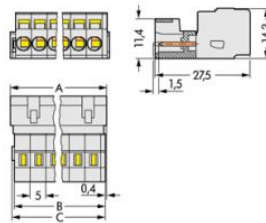

Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

RoHS compliant

Product group	3 (Multi Conn. System)
Weight	5.05 g
Color	light gray
No. of connection Points	3
No. of potentials	3
pole count	3
Height	14.3 mm
Height	0.563 in
Width	18.2 mm
Width	0.717 in
Depth	27.5 mm
Depth	1.083 in
Pin spacing from	5 mm
Pin spacing from	0.197 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	12 A

Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	12 A



Connection method	CAGE CLAMP® CONNECTION
Cross section [mm <sup>2</sup> ]	0.08 - 2.5 mm <sup>2</sup>
Wiring method	solid
Cross section [mm <sup>2</sup> ]	0.08 - 2.5 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 1.5 mm <sup>2</sup>
Cross section [mm <sup>2</sup> ]	0.25 - 2.5 mm <sup>2</sup>
Cross section [AWG]	28 - 12 AWG
Strip length from	8 mm
Strip length to	9 mm
Material group	I
xxx-xxx/032-000	Strain relief plate 11,5 mm



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [ mm <sup>2</sup> ]
721-603	ABS	04-HG469925/1-PDA	250	12	0,08-2,5
721-603	BV	11915/A0	250	12	
721-603	CCA	5764	250	12	0,08-2,5
721-603	CSA	154112-1466354	300	15	28-12
721-603	DNV	E-9218	250	12	0,08-2,5
721-603	GL	17296-00HH	250	12	
721-603	KEMA	2083746.02	250	12	0,08-2,5
721-603	KR	HMB05880-EL003	250/400	12/16	2,5
721-603	LR	96/20035	250	12	0,08-2,5
721-603	RMR	11130002	250	12	0,08-2,5
721-603	UR	E45171	600	20	12
721-603	UR	E45172	300	15	28-12

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected