

**H16,0/15****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

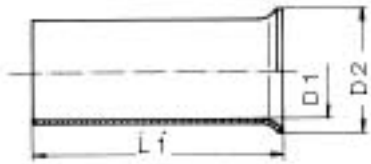

For conductors from 10.0 to 185.0 mm<sup>2</sup> (AWG 7 - 350 MCM)

tin-plated copper

dimensional tolerances to DIN 46228 part 1

- supplied loose in poly-bag

**General ordering data**

Order No.	<a href="#">0124300000</a>
Type	H16,0/15
Version	Wire end ferrule, 16 mm <sup>2</sup>
GTIN (EAN)	4008190162993
Qty.	500 pc(s).

**H16,0/15**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 16  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Technical data**

**Dimensions and weights**

Length	15 mm	Net weight	0.502 g
--------	-------	------------	---------

**Product data**

Conductor cross-section	16 mm <sup>2</sup>	Wire connection cross section AWG, max.	AWG 6
Contact surface diameter (D1)	5.8 mm	Collar diameter (D2)	7.5 mm

**Classifications**

ETIM 2.0	EC000005	ETIM 3.0	EC000005
UNSPSC	31-16-31-02	eClass 4.1	27-06-07-01
eClass 5.1	27-40-02-01	eClass 6.0	27-40-02-01
eClass 7.0	27-40-02-01		

**Product information**

Description of article	Wire end ferrule without plastic collar
------------------------	---

**Approvals**

Approvals

