

BG GHDE 10P PT6**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

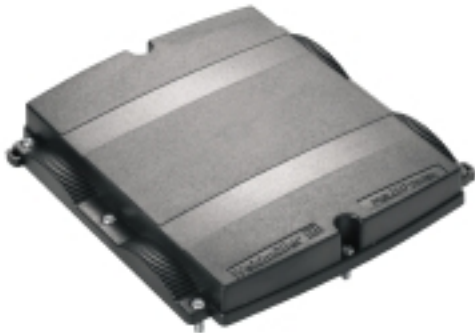

The FieldPower® housings are highly robust and meet the highest UL flammability class 5 VA.

- The "TS 35 PT6" mounting rail module and PT6 contact unit are easy to snap on.
- Hinged seals allow pre-assembled plug cables to also be used.
- The high cover versions enable the device to be installed.

For cable seals consult accessories.

General ordering data

Type	BG GHDE 10P PT6
Order No.	1122200000
Version	Enclosures, IP65 with corresponding housing, Polycarbonate, GF 10
GTIN (EAN)	4032248903207
Qty.	10 pc(s).

Creation date August 3, 2020 12:22:28 AM CEST

Catalogue status 24.07.2020 / We reserve the right to make technical changes.

BG GHDE 10P PT6**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Technical data**Dimensions and weights**

Length	181 mm	Length (inches)	7.126 inch
Width	192 mm	Width (inches)	7.559 inch
Height	181 mm	Height (inches)	7.126 inch
Depth	25 mm	Depth (inches)	0.984 inch
Net weight	235.1 g		

Temperatures

Operating temperature, max.	85 °C	Operating temperature, min.	-40 °C
Storage temperature, max.	85 °C	Storage temperature, min.	-40 °C
Operating temperature	-40 °C...85 °C	Storage temperature	-40 °C...85 °C

General specifications

Halogen	No	Insulating material	Polycarbonate, GF 10
Protection degree	IP65 with corresponding housing	Silicone	No
Colour	black	UL 94 flammability rating	5VA
Lid attachment	Cross-head screws PZ2		

Classifications

ETIM 6.0	EC000747	ETIM 7.0	EC000747
eClass 9.0	27-18-22-04	eClass 9.1	27-18-92-90
eClass 10.0	27-18-22-04		

Approvals

Approvals



ROHS

Conform

Downloads

Approval/Certificate/Document of Conformity

[FieldPower](#)

Engineering Data

[WSCAD](#)

BG GHDE 10P PT6

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

Drilling template

