

**Tools**  
**MULTI-STRIPAX AWG****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26


D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

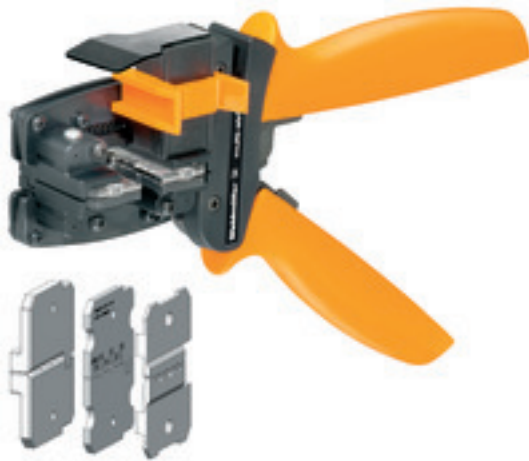

- For flexible and solid conductors with special insulating materials
- High-quality stripping for industrial applications (complies with aircraft industry requirements)
- Specially shaped blades enable stripping of special types of insulation and conductor configurations
- Stripping length adjustable via end stop
- Very versatile thanks to interchangeable stripping units
- Stripping results reproduced accurately over and over again
- No damage to the conductor
- A long-lasting, reliable tool thanks to its sturdy design
- Integrated cutting function

**General ordering data**

Type	MULTI-STRIPAX AWG
Order No.	<a href="#">9202230000</a>
Version	Tools, Stripping and cutting tool, AWG conductor with PTFE and PVC insulation
GTIN (EAN)	4032248486168
Qty.	1 pc(s).

Creation date April 21, 2020 2:22:14 PM CEST

Catalogue status 17.04.2020 / We reserve the right to make technical changes.

**Tools**  
**MULTI-STRIPAX AWG**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

**Technical data**

**Dimensions and weights**

Width	250 mm	Width (inches)	9.842 inch
Height	85 mm	Height (inches)	3.346 inch
Depth	40 mm	Depth (inches)	1.575 inch
Weight	250 g	Net weight	520.28 g

**Environmental Product Compliance**

REACH SVHC Lead 7439-92-1

**Stripping tools**

Cable type	AWG conductor with PTFE and PVC insulation	Conductor cross-section (cutting capacity)	6 mm <sup>2</sup>
Copper cable - flexible, max.	6 mm <sup>2</sup>	Stripping length, min.	2 mm
Stripping range AWG, max.	16 AWG	Stripping range AWG, min.	26 AWG
max. cutting capacity, fine-strand	6 mm <sup>2</sup>	max. cutting capacity, ribbon	10,2 mm x 4 mm
max. cutting capacity, solid	2.5 mm <sup>2</sup>		

**Classifications**

ETIM 6.0	EC002109	ETIM 7.0	EC002109
eClass 9.0	21-04-37-06	eClass 9.1	21-04-37-06
eClass 10.0	21-04-37-06	UNSPSC	23-17-16-04

**Approvals**

Approvals



**Downloads**

Brochure/Catalogue	<a href="#">CAT 6 TOOLS 15/16 EN</a>
User Documentation	<a href="#">Manual</a>

**Data sheet**

**Tools**  
**MULTI-STRIPAX AWG**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

**Example of use**

---

