

WEB SPECIALS

- 1 | 2 | 3 | 4 | 5 | 6 | 7 | 8 | 9
- 10 | 11 | 12 | 13 | 14 | 15
- 16 | 17 | 18 | 19 | 20 | 21

Screwdriver Bits

- Terminator Impact Bits
- Bit Holders
- Bits 1" Screwdriver Style
- Bits 2 to 6" Power Bits
- Bits - All Bit Sets
- Bits Stainless Steel
- Bits Specialty
- Bits Carbide Coated
- Bits Titanium Coated
- Bits Drills & Countersinks
- Bits Nut Setters 2" - 12"

Hex Tools

- Hex - Ball End Tools
- Hex - Standard Tools
- Hex - Screw Holding
- Hex - Security Tools
- Hex - Stainless Steel

TORX Tools

- Torx Standard Tools
- Torx Ball Ends
- Torx Plus Tools
- Torx Security Tools
- Torx Screw Holding Tools

Crimp Tools

- Porta Crimp Dies & Frame
- Ratchet Crimp Tools
- Data Pro Crimp Tools
- Stripping Tools
- Coax 2 Step Strip Tools
- Coax 3 Step Strip Tools
- Adjustable Strip Tool
- Auto Strip Tool
- Cable Jacket Stripper

Insulated Tools

- Insulated Slotted Drivers
- Insulated Phillips Drivers
- Insulated Terminal Drivers
- Insulated Nut Drivers Inch
- Insulated Torx Drivers MM
- Insulated Torx Drivers
- Insulated Square Drivers
- Insulated T-Handle Hex
- Insulated Pliers & Cutters
- Insulated Inomic Tools
- Insulated Protum Tools
- Insulated Sets
- Insulated 1/4" Sockets
- Insulated 3/8" Sockets
- Insulated 1/2" Sockets
- Insulated Ratchets
- Insulated Knives
- Insulated Open Wrenches
- Insulated Gear Wrenches
- Insulated Deep Off Sets
- Insulated Adjustable
- Insulated Hex Keys
- Insulated Cable Cutters

Stainless Steel Tools

- Stainless Insert Bits
- Stainless Power Bits
- Stainless Screwdrivers
- Stainless Hex Keys

Premium Tool Designs

- ACO Anti Cam Out Drivers
- Awls - Square & Round
- BitFlip Driver Sets
- Cabinet Tip Drivers
- ClicFix Quick Release
- Counter Sinks & Drills
- Customized Tool Sets
- Drills & Countersinks
- Drive-Loc VI Tools
- Dynamic Tech Drivers
- ESD Safe Tools
- MagicRing Screw Holding
- MagicTip Ring Pliers
- Magnetizer Demagnetizer
- Micro Bit Precision Tools
- Microfinish Non Slip Grips
- Miscellaneous Tools
- Precision Tech Drivers
- Precision Pouch Sets
- Precision Standard Sets
- Protum Economy Torx
- Screw Holding Drivers
- Sockets & Sets
- SoftFinish Cushion Grips
- Stubby Bit Holders Sets
- System 4 Precision Drivers
- System 4 ProTurn
- T-Handles Cushioned Grips
- T-handles Standard Grips
- Torque Control Drivers
- 3K Ergo Screwdrivers
- Topra Gearless Ratchet
- TORX Wing or Flag
- X-Selector Bit Sets

Measuring

- Water Proof Rulers
- Calipers Digital, Dial, Vern

WEB SPECIALS

- 1 | 2 | 3 | 4 | 5 | 6 | 7 | 8 | 9
- 10 | 11 | 12 | 13 | 14 | 15
- 16 | 17 | 18 | 19 | 20 | 21



Search Wiha Site



Tools that work for you

Secure Shopping

UPS \$5.99

\$100 Ships Free

View Cart



- Home
- On Sale
- Catalog
- Search
- About US
- \$1000
- Warranty
- Products
- Hot Stuff!

"SoftFinish" Metric Cushion Grip Nut Drivers.



Solid Shafts & Heavy Duty Forged Sockets

- Finally a Handle that makes Nut Drivers Useful, 40% More Power
- Cushion grip with soft ergonomic molded shape.
- Heavy duty Solid Shaft of High Performance tool steel.
- Through hardened for maximum torque and best wear resistance.
- Deep forged heavy duty sockets guaranteed never to split.
- Nickel Plated anti corrosion finish
- Satisfaction Guaranteed • Made In Germany

| Item No. | Style | Size | Blade Length | Over All Length | Add To Cart 25.4mm = 1" |
|----------|----------------------|-------|--------------|-----------------|---|
| 34120 | Nut driver Soft Grip | 5mm | 125mm | 236mm | \$7.56 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34121 | Nut driver Soft Grip | 5.5mm | 125mm | 236mm | \$7.56 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34122 | Nut driver Soft Grip | 6mm | 125mm | 236mm | \$7.92 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34123 | Nut driver Soft Grip | 7mm | 125mm | 236mm | \$7.92 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34124 | Nut driver Soft Grip | 8mm | 125mm | 236mm | \$7.92 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34125 | Nut driver Soft Grip | 9mm | 125mm | 243mm | \$7.94 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34126 | Nut driver Soft Grip | 10mm | 125mm | 243mm | \$8.16 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34127 | Nut driver Soft Grip | 11mm | 125mm | 243mm | \$9.24 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34128 | Nut driver Soft Grip | 12mm | 125mm | 243mm | \$9.60 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34129 | Nut driver Soft Grip | 13mm | 125mm | 249mm | \$10.00 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34130 | Nut driver Soft Grip | 14mm | 125mm | 249mm | \$11.74 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34131 | Nut driver Soft Grip | 15mm | 125mm | 249mm | \$12.54 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34132 | Nut driver Soft Grip | 16mm | 125mm | 249mm | \$15.26 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34133 | Nut driver Soft Grip | 17mm | 125mm | 249mm | \$15.48 <input type="text" value="1"/> <input type="button" value="Add"/> |

Magnetic Metric Cushion Grip Nut Drivers


| | | | | | |
|-------|---------------------|-------|-------|-------|---|
| 34152 | Magnetic Nut Driver | 5.5mm | 125mm | 236mm | \$18.98 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34154 | Magnetic Nut Driver | 5.5mm | 250mm | 360mm | \$21.98 <input type="text" value="1"/> <input type="button" value="Add"/> |
| 34158 | Magnetic Nut Driver | 7mm | 125mm | 236mm | \$19.98 <input type="text" value="1"/> <input type="button" value="Add"/> |

Ergo Cushion Grip Nut Driver Sets

- Professional Series Wiha Nut Drivers
- Molded On Soft Ergo Cushion Grips
- Guaranteed Quality - Made by Wiha
- Exact Fit precision Machined Fit
- Made of Chrome-Moly Tool Steel
- Through Hardened Durability

Flex Shaft SoftFinish Grip Nut Drivers

- Inch & Metric With Flexible Shafts
- Forged Sockets Heavy Duty sockets
- Round Rubber Coated Flex Shafts
- Ideal For reaching Obstructed Fasteners
- Molded On Ergo SoftFinish Grip Handles
- Guaranteed Quality - Made In Germany

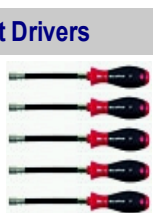

#37291 Metric Flex Soft Grip Nut Drivers
7pc Metric Flex Nut Drivers Set
Includes: 5, 5.5, 6, 7, 8, 10, 13.0mm
\$156.50 #37291

Free Freight

#37290 Inch Soft Grip Nut Drivers
6pc Inch Flex Nut Driver Set
Includes: 3/16, 1/4, 5/16, 3/8, 7/16, 1/2
\$163.36 #37290

Free Freight

Heavy Duty Solid Shaft SoftFinish Grip Nut Drivers

- Inch & Metric Solid Shafts,
- 1" Deep Forged Sockets,
- Hex Bolster for extra force,
- Made from Premium CRM-72 Tool Steel
- Through Hardened Durability
- Molded On Ergo SoftFinish Grip Handles
- Guaranteed Quality - Made In Germany



#34791 Heavy Duty Cushion Grip
With Hex Bolsters & Solid Shafts
5pc Metric Nut Drivers Set
Includes: 5.0, 6.0, 8.0, 10.0, 11.0mm
\$63.16 34791

#34792 Heavy Duty Cushion Grip
With Hex Bolsters & Solid Shafts
6pc Inch Nut Driver Set
Includes: 3/16, 1/4, 5/16, 3/8, 7/16, 1/2
\$80.56 34792

Solid Round Shaft SoftFinish Ergo Grip Nut Drivers

- Inch & Metric With Solid Shafts
- 1" Deep Well Forged Sockets
- Round Blades CRM-72 Tool Steel
- Through Hardened Durability
- Molded On Ergo SoftFinish Grip Handles
- Guaranteed Quality - Made In Germany



#34194 Metric Soft Grip Nut Drivers
7pc Metric Nut Drivers Set
Includes: 5, 5.5, 6, 7, 8, 10, 13mm
\$56.04 34194

#34193 Inch Soft Grip Nut Drivers
7pc Inch Nut Driver Set
Includes: 3/16, 1/4, 5/16, 11/32, 3/8, 7/16, 1/2
\$57.78 34193

#34195 Inch Soft Grip Nut Drivers
10 pc Inch Nut Driver Set
Includes: 3/16, 7/32, 1/4, 5/16, 11/32, 3/8, 7/16, 1/2, 9/16, 5/8
\$88.48 34195

Hollow Shaft Soft Finish Ergo Grip Nut Drivers

- Inch & Metric With Hollow Shafts
- Hard Chromed Shafts
- High Performance Tool Steel
- Hardened Durability
- Molded On Ergo SoftFinish Grip Handles
- Guaranteed Quality - Made In Germany



#34391 Metric Soft Grip Nut Drivers
7pc Metric Nut Drivers Hollow Shaft Set
Includes: 5, 5.5, 6, 7, 8, 10, 13.0mm
\$61.98 34391

#34390 Inch Soft Grip Nut Drivers
7pc Inch Nut Driver Hollow Shaft Set
Includes: 3/16, 1/4, 5/16, 11/32, 3/8, 7/16, 1/2
\$63.58 34390

More Ergo Soft Grip Styles To Choose From

| | | |
|--|---------------------------------|--|
| Phillips Standard | 1/4 Bit Holder | Nut Drivers Standard MM |
| Phillips Heavy Duty | TORX Security | Nut Drivers Standard Inch |
| Phillips Extra Heavy Duty | TORX Standard | Nut Drivers Heavy Duty MM |
| Phillips Screw Holding | TORX Plus | Nut Drivers Heavy Duty Inch |
| Slotted Standard | Torx Screw Hold | Nut Drivers Flex Shaft MM |
| Slotted Heavy Duty | Square Tip | Nut Drivers Flex Shaft Inch |
| Slotted Extra Heavy Duty | ESD Slotted | Torque Control Insulated |
| Slotted Screw Holding | ESD Phillips | Torque Control Standard |
| Soft Grip Scraper | ESD TORX | Torque Control ESD |
| Soft Grip Pozidriv | Screw Hold Hex | Soft Grip Hex Drivers Metric |
| Soft Grip Hollow Nut Drivers | SoftFinish Sets | Soft Grip Hex Drivers Inch |
| Soft Grip Hollow MM Drivers | Drive-Loc | Soft Grip Stubby Sets |

[See Complete Nut Driver Product Index](#)

[See Metric Hollow Shaft Nut drivers](#)

[See Screwdriver Index](#)

[Go To Main Tool Index](#)

Add Complete Product Guide To My Cart

Join our Members Only list

Receive new product up dates and announcements of Special Super buy opportunities. Your information is confidential.

Name

E-mail



[Warranty](#) | [Returns](#) | [Privacy](#) | [Shipping](#) | [Search](#) | [Specials](#)

Featured Products

WEB SPECIALS

- 1 | 2 | 3 | 4 | 5 | 6 | 7 | 8 | 9
- 10 | 11 | 12 | 13 | 14 | 15
- 16 | 17 | 18 | 19 | 20 | 21

Screwdriver Styles

- Hex Standard
- Hex Ball Ends
- Stainless Screwdrivers
- Nut Drivers
- Phillips Tools
- Pozi Driv Tools
- Slotted Tip Tools
- Square Tip Tools
- Torx Standard
- Torx Ball Ends
- Torx Security
- Torx Plus
- Tri-Wing & Torq-Set
- SoftFinish Grips
- Non-Slip Grips
- Precision Tech
- 40 Pc Industrial Set

Torque Control

- Torque Digital Torque
- Economy Preset Drivers
- Preset Drivers
- Preset T-Handle
- Adjustable Inch Lbs
- Adjustable Inch Lbs ESD
- Adjustable Insulated
- Adjustable Newton Meters
- Torque Blades & Adapters
- Torque Control Torx
- Torque Control Torx Plus

Pliers & Cutters

- Inomic Insulated Pliers
- Standard Vinyl Grip Pliers
- Precision Pliers & Cutters
- ESD Pliers & Cutters
- Insulated Pliers & Cutters
- SoftGrip Pliers & Cutters
- Retaining Ring External
- Retaining Ring Internal
- MagicTip Snap Ring Pliers
- Pipe Wrenches

Professional Sockets

- 1/4 Drive Inch
- 1/4" Drive Metric
- 1/4" Accessories
- 3/8" Drive Inch
- 3/8" Drive Metric
- 3/8" Accessories
- 1/2" Drive Inch
- 1/2" Drive Metric
- 1/2" Accessories
- 1/4" 3/8" 1/2" Bit Sockets

Dead Blow Hammers

- Dead Blow Cushion Grips
- Dead Blow Hickory
- Replacement Faces

Split Head Mallets

- Split Head Mallets
- Replacement Faces
- Replacement Heads
- Replacement Handles

Precision Metric Punches

- Tapered Pin Punches
- Parallel Pin Punches
- Center Punches

MaxiFlex Coolant Hose

- 1/4" Diameter Hose
- 1/2" Diameter Hose

Tweezers & Instruments

- Cutting Tweezers
- ESD Safe Tweezers
- Foil Thin Tweezers
- Guide Pin Tweezers
- Long Tweezers
- Micro Tip Tweezers
- Standard Tweezers
- Component Tweezers
- Wafer Tweezers
- Self Closing Tweezers
- Hooks, Probes, Shapers
- Inspection Mirrors

Wrenches

- Open End Metric
- Open End Inch
- Combination Metric
- Combination Inch
- Box End Metric
- Box End Inch
- Cushion Grip Metric
- Cushion Grip Inch
- Pipe Wrenches
- Insulated Open Wrenches
- Insulated Gear Wrenches
- Insulated Adjustables
- Insulated Deep Off Sets

Cutting Tools 1/4" Drive

- Drills/Countersinks



Search Wiha Site

Contact e-mail
cservice@whatools.com
Fax: 763-295-6598
Tel: 763-295-6591
Whatools.com LLC
1348 Dundas Circle
Monticello, MN 55362 USA