

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130039-0299](#)
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: DeviceNet® Trunk Receptacle, 5 Poles, 1/2" - 14 NPT, Male (Straight) to Leads, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Receptacles
 Series [130039](#)
 IP Rating IP67
 NEMA Rating NEMA 6
 Overview [Brad® Mini-Change® Connectors](#)
 Product Name DeviceNet® Trunk
 Type Single Ended (pigtail)
 UPC 78678828754

Physical

Coupling Type External Thread
 Gender Male
 Keyway Single
 Length 1.0m
 Material - Component Gray Anodized Aluminum
 Mounting Thread Size 1/2" - 14 NPT
 Net Weight 43.640g
 Orientation Straight
 Panel Mount Front
 Poles 5
 Temperature Range - Operating -20°C to +80°C
 Wire Size AWG 18
 Wire/Cable Type Thick Standard Cable

Electrical

Current - Maximum per Contact 8A
 Voltage - Maximum 300V AC/DC

Material Info

Old Part Number DN5100-M010

Reference - Drawing Numbers

Sales Drawing SD-130039-001


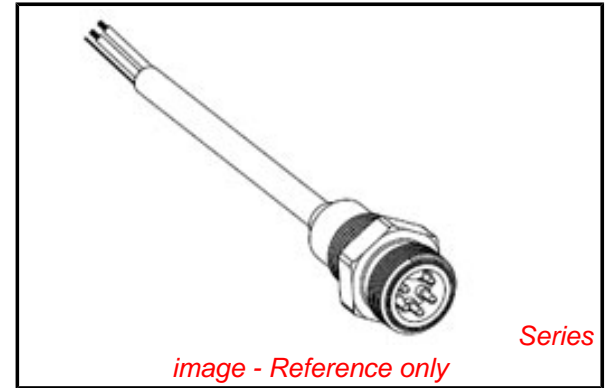


image - Reference only

EU RoHS

RoHS Compliant by Exemption
REACH SVHC
 Not Reviewed
Low-Halogen Status
Not Reviewed

China RoHS

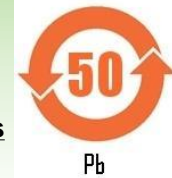

Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

130039Series