

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130000076](#)
Status: **Active**
Overview: [Brad Quick-Change Connectors](#)
Description: Quick-Change Single-Ended Cordset, 4 Poles, Female (Straight) to Pigtail, 14 AWG, CPE Cable, 3.66m (12.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E46237

General

Product Family Industrial Cordsets
 Series [130000](#)
 Connector End A Quick-Change
 Connector End B Pigtail
 IP Rating IP67
 Material - Contact Copper Alloy
 Overview [Brad Quick-Change Connectors](#)
 Product Name Quick-Change
 Protocol N/A
 Region America
 Type Single Ended
 UPC 78678832639

Physical

Cable Diameter 15.74mm (.620")
 Cable Length 3.66m (12.0')
 Color - Cable Jacket Yellow
 Coupling Style Threaded
 Gender Female-Pigtail
 Keyway Single
 LED Indicator No
 Material - Cable Jacket CPE
 Material - Connector Body Thermoplastic Elastomer
 Material - Coupling Nut Nylon
 Material - Plating Mating N/A
 Net Weight 477.000/g
 Orientation Straight to Pigtail
 Poles 4
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 14
 Wire/Cable Type SOW

Electrical


Current - Maximum per Contact 15.0A
 Voltage - Maximum 600V

Material Info

Engineering Number 32639

Reference - Drawing Numbers

Sales Drawing SD-130000-004

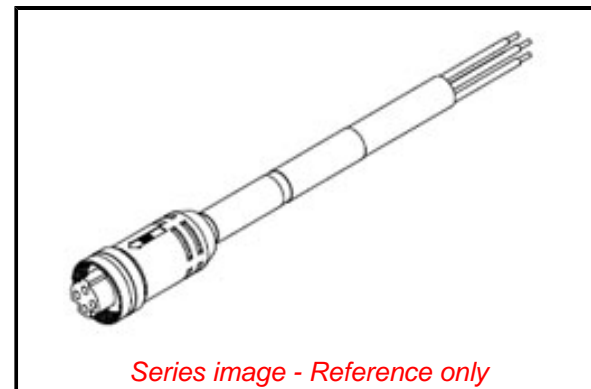

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130000 Series](#)

This document was generated on 07/29/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION