

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300100228](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change A-Size Double-Ended Cordset, 3 Poles, Male (Straight) to Female (Straight), 16 AWG, PVC Cable, 3.66m (12.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Cordsets
 Series [130010](#)
 Connector End A Mini-Change
 Connector End B Mini-Change
 IP Rating IP67
 Material - Contact Copper Alloy
 Overview [Brad Mini-Change Connectors](#)
 Product Name Mini-Change
 Protocol N/A
 Region America
 Type Double Ended
 UPC 78172553126

Physical

Cable Diameter 10.41mm (.410")
 Cable Length 3.66m (12.0')
 Color - Cable Jacket Yellow
 Coupling Style Threaded
 Gender Female-Male
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold over Nickel
 Net Weight 564.268/g
 Orientation Straight to Straight
 Poles 3
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 16
 Wire/Cable Type STOOW

Electrical


Current - Maximum per Contact 13.0A
 Voltage - Maximum 600V

Material Info

Engineering Number 113020A01F120

Reference - Drawing Numbers

Sales Drawing SD-130010-002

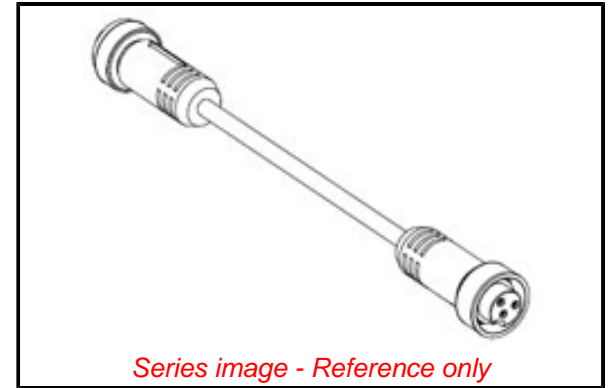

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130010 Series](#)

This document was generated on 01/29/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION