

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300250295](#)

Status: **Active**

Overview: [Brad Mini-Change Connectors](#)

Description: Mini-Change Double-Ended Cordset, 5 Poles, Male (Straight) to Female (Straight), 22 AWG, DeviceNet Standard Cable, 5.0m (16.40') Length

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
UL E152210

General

Product Family Industrial Cordsets
Series [130025](#)
Connector End A Mini-Change
Connector End B Mini-Change
IP Rating IP67
Material - Contact Brass
Overview [Brad Mini-Change Connectors](#)
Product Name DeviceNet Trunk, Mini-Change
Region Europe
Type Double Ended
UPC 78678801099

Physical

Cable Diameter 7.62mm (.300")
Cable Length 5.0m (16.40')
Color - Cable Jacket Gray
Coupling Style Threaded
Gender Female-Male
Keyway Single
LED Indicator No
Material - Cable Jacket PVC
Material - Connector Body PVC
Material - Coupling Nut Die-Cast Zinc
Material - Plating Mating Gold
Net Weight 408.686/g
Orientation Straight to Straight
Poles 5
Temperature Range - Operating -20°C to +80°C
Wire Size AWG 22
Wire/Cable Type Thin (Drop)

Electrical


Current - Maximum per Contact 4.0A
Voltage - Maximum 300V AC/DC

Material Info

Engineering Number DND11A-M050

Reference - Drawing Numbers

Sales Drawing SD-130025-019-001

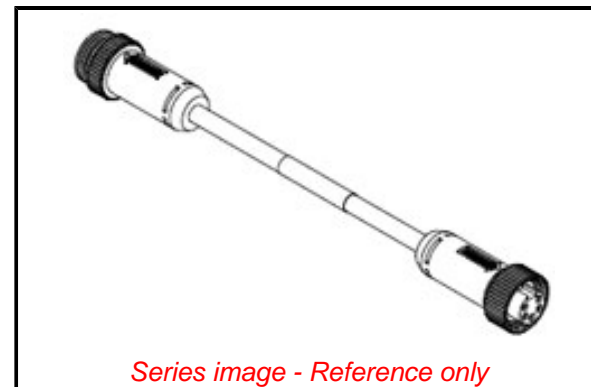

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per -ED/88/2018 (15 January 2019)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Contained: DEHP

Search Parts in this Series

[130025 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION