

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300545003](#)
Status: **Active**
Overview: Brad Industrial Ethernet Solutions
Description: Ultra-Lock (M12) to RJ-45 Industrial Ethernet Double-Ended Cordset, Female (Straight) to RJ-45 Male (Straight), 24 AWG, PVC Cable, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	130054
Connector End A	Ultra-Lock (M12)
Connector End B	RJ-45 (industrial)
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Industrial Ethernet, Ultra-Lock (M12)
Protocol	N/A
Region	America, Asia, Europe
Type	Double Ended
UPC	883906399139

Physical

Cable Diameter	N/A
Cable Length	1.0m (3.28')
Color - Cable Jacket	Teal
Coupling Style	Threaded
Gender	Female-Male
Keyway	D-coded
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PVC
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold over Nickel
Net Weight	156.600/g
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-25°C to +75°C
Wire Size AWG	24
Wire/Cable Type	E152210

Electrical


Current - Maximum per Contact	1.5A
Voltage - Maximum	150V AC

Material Info

Engineering Number	ERWPAU7003M010
--------------------	----------------

Reference - Drawing Numbers

Sales Drawing	SD-120109-013
---------------	---------------

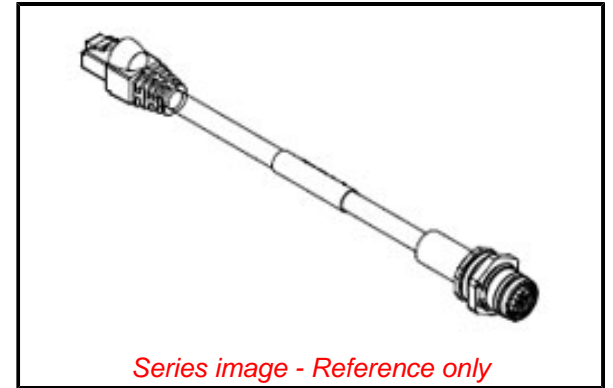

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - ED/71/2019 (16 July 2019)

Lead

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

50 Image

Not Relevant

Not Contained

Search Parts in this Series

[130054](#) Series