

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300580025](#)
Status: **Active**
Description: Ultra-Lock (M12) D-Coded to RJ-45 Adapter, Straight to Straight, 4 PoleFemale to RJ45 Male, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E200650

General

Product Family Industrial Receptacles
 Series [130058](#)
 IP Rating IP67
 Product Name RJ45, Ultra-Lock (M12)
 Type Adapter
 UPC 78678802441

Physical

Coupling Type Push to Lock
 Gender Female-Male
 Keyway D-coded
 Length 1.0m
 Material - Component Nylon
 Mounting Thread Size N/A
 Net Weight 150.000/g
 Orientation Straight
 Panel Mount N/A
 Poles 4
 Temperature Range - Operating N/A
 Wire Size AWG N/A
 Wire/Cable Type N/A

Electrical


Current - Maximum per Contact N/A
 Voltage - Maximum N/A

Material Info

Engineering Number ERWPAB3002M010

Reference - Drawing Numbers

Sales Drawing SD-130054-002

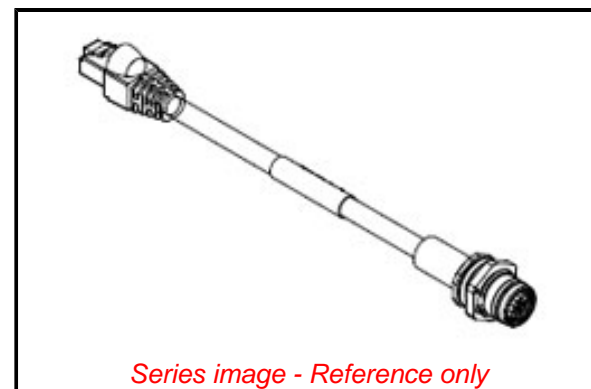

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - ED/71/2019 (16 July 2019)

Lead

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[130058 Series](#)