

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300980195](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: MAX-LOC Multi-Hole Strain Relief, 1/2" NPT, Straight Male, Cable Diameter 5.72mm (.225")

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159
 UL E76954

General

Product Family Cable Grips
 Series [130098](#)
 Comments Indicates that one or more grommet hole is covered by a thin membrane which can easily be "Poked" open if required., Indicates that one or more grommet hole is covered by a thin membrane which can easily be "Poked" open if required.
 Exclude SD Check Yes
 Eye Type N/A
 NEMA Rating NEMA 3R
 O-Ring No
 Overview [Strain-Relief Cord Grips](#)
 Product Literature Order No 987651-6081
 Product Name MAX-LOC
 Type Strain Relief Grip
 UPC 78678850409
 Use With 1/2" NPT MAX-LOC Lock Nut [1300990143](#) , MAX-LOC O-Ring, 1/2" NPT [1301800314](#) , 1/2" NPT MAX-LOC Gasket [1300990149](#)

Physical


Approximate Break Strength N/A
 Bale Length N/A
 Body Style Straight
 Cable Diameter 5.72mm (.225")
 Color - Grommet Yellow
 Gender Male
 Material - Body Nylon
 Material - Grip N/A
 Mesh Length N/A
 Number of Holes 2, 3, or 4
 Thread Size 1/2" NPT

Material Info

Engineering Number 5594-004

Reference - Drawing Numbers

Sales Drawing SD-130098-195

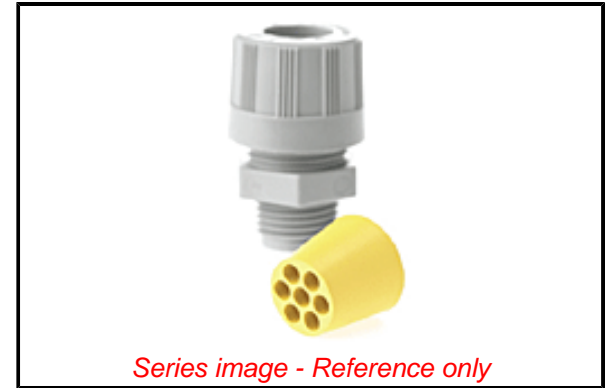

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130098 Series](#)