

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130099-0180](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: MAX-LOC®/Watertite® Cord Grips, 1" NPT, Straight Male, Body Size F4, Cable Diameter 15.88-19.05mm (.625-.750"), Non-Metallic

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159
 UL E76954

General

Product Family Cable Grips
 Series [130099](#)
 Eye Type N/A
 NEMA Rating NEMA 3R
 O-Ring N/A
 Overview [Strain-Relief Cord Grips](#)
 Product Literature Order No 987650-8064
 Product Name MAX-LOC®, Watertite®
 Type Strain Relief Grip
 UPC 78678872107
 Use With MAX-LOC® Lock Nut 1" NPT [130099-0145](#) , MAX-LOC® Gasket Sealing Ring 1" NPT [130099-0151](#) , MAX-LOC® O-Ring, 1" NPT [130180-0334](#)
 Woodhead Yes

Physical


Approximate Break Strength N/A
 Bale Length N/A
 Body Style Straight
 Cable Diameter 15.88-19.05mm (.625-.750")
 Color - Grommet N/A
 Gender Male
 Material - Body Nylon
 Material - Grip Nylon
 Mesh Length N/A
 Number of Holes 1
 Thread Size 1" NPT

Material Info

Old Part Number 5637NM

Reference - Drawing Numbers

Sales Drawing SD-130099-008

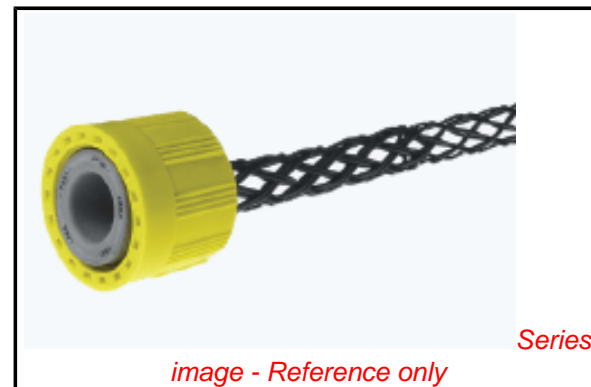

EU RoHS

ELV and RoHS Compliant
REACH SVHC Not Reviewed
Low-Halogen Status Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[130099Series](#)