

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301020261](#)
Status: **Active**
Overview: [Hand Lamps](#)
Description: Safeway Phenolic Hand Lamp with 100W, Screw Release Guard with Reflector, with Switch and Side Outlet, Cord Type 16/3 SJTOW, Cord Length 15.24m (50.0')

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification

CSA LR85374

General

Product Family Portable Lighting
Series [130102](#)
Exclude SD Check Yes
NEMA Configuration NEMA 5-15
Outlet Side
Overview [Hand Lamps](#)
Product Literature Order No 987650-8053
Product Name Safety Yellow
Type Hand Lamps
UPC 78678879533

Physical


Cord Length - Primary 15.24m (50.0')
Cord Length - Secondary N/A
Depth 101.60mm (4.000")
Duty Commercial
Guard Included Yes
Guard Type Reflector, Screw Release
Height 381.00mm (15.000")
Length N/A
Material - Guard #8 Gauge Zinc-plated Steel
Mounting Style Hand Held
Packaging Type Carton
Socket Construction N/A

Electrical

Bulb Type Incandescent
Cord Type - Primary 16/3 SJTOW
Lamp Type A21
Lamp Wattage - Maximum 100W
Lumens 1000
On/Off Switch Yes
Voltage (Fixture) - Maximum 240V

Material Info

Engineering Number 271USB163

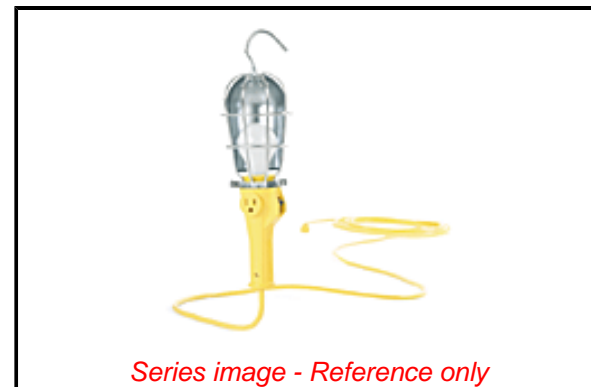

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130102 Series](#)