

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301100050](#)  
**Status:** **Active**  
**Overview:** [Wide-Area Lighting Products](#)  
**Description:** Pro-Yellow 400W Metal Halide High Bay Light with Lamp Molded 18/3 SJTW 1.83m (6.0') Pulse Start

**Documents:**

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)  
[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

UL E174253

**General**

Product Family Portable Lighting  
 Series [130110](#)  
 Exclude SD Check Yes  
 NEMA Configuration NEMA 5-15  
 NEMA Rating Rain Tight  
 Outlet None  
 Overview [Wide-Area Lighting Products](#)  
 Product Literature Order No 987650-8054  
 Product Name Pro-Yellow  
 Type Wide Area Lamps  
 UPC 78172505741

**Physical**

Cord Length - Primary 0.91m (3.0')  
 Cord Length - Secondary N/A  
 Depth N/A  
 Duty General  
 Guard Included Yes  
 Guard Type Steel  
 Height 463.55mm (18.250")  
 Length N/A  
 Material - Guard #10 Gauge Zinc-plated Steel  
 Mounting Style Hook  
 Net Weight 6477.293/g  
 Packaging Type Carton  
 Socket Construction N/A

**Electrical**


Bulb Type Metal Halide - Pulse Start  
 Cord Type - Primary 16/3 SOOW  
 Lamp Type BT37/ED-37 Type O  
 Lamp Wattage - Maximum 400W  
 Lumens 26000  
 On/Off Switch No  
 Voltage (Fixture) - Maximum 120VAC 60 HZ

**Material Info**

Engineering Number 8575-MH-PS

**Reference - Drawing Numbers**

Sales Drawing SD-130110-002

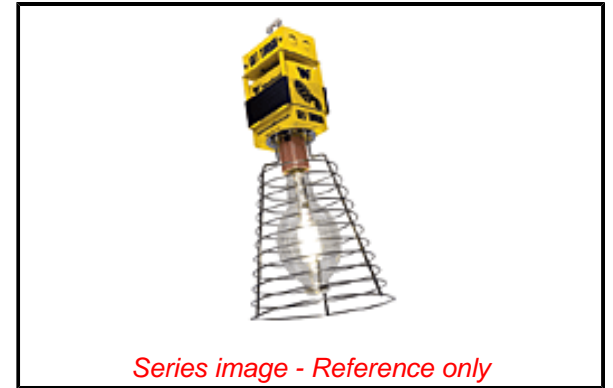

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130110 Series](#)

This document was generated on 09/18/2019

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**