

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301370163](#)  
**Status:** **Active**  
**Overview:** [Watertite Wet-Location Wiring Solutions](#)  
**Description:** Watertite Multiple Outlet Box, Extended Depth, (1) NEMA 5-15 Manual reset GFCI with Flip Lid, Open Neutral Relay, 1.83M (6.0') Cord Length, 12/3 SOOW Cord, 5-15 Plug

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)      [Product Literature \(PDF\)](#)

**Agency Certification**

CSA      LR6837

**General**

Product Family      Power Distribution  
 Series      [130137](#)  
 Enclosure Rating      N/A  
 Exclude SD Check      Yes  
 GFCI Reset      Manual  
 Mounting Style      Portable  
 Open Neutral Relay      Yes  
 Overview      [Watertite Wet-Location Wiring Solutions](#)  
 Product Literature Order No      987650-7737  
 Product Name      Watertite  
 Receptacle Type      Duplex  
 Type      Multiple Outlet Box  
 UPC      78678830709

**Physical**


Cord Diameter      15.24mm (.600")  
 Cord Grip Body Size      F3 3/4"  
 Cord Length      1.83m (6.0')  
 Feed-Thru      Yes  
 Flip Lid      Yes  
 Material - Housing      Rubber  
 Number of Receptacles      1  
 Packaging Type      Carton

**Electrical**

Cord Type      12/3 SOOW  
 Current - Maximum per Contact      N/A  
 GFCI      Yes - Receptacle  
 Ground Continuity Monitor      No  
 NEMA Configuration      NEMA 5-15  
 Voltage - Maximum      125V

**Material Info**

Engineering Number      3070W-GFI

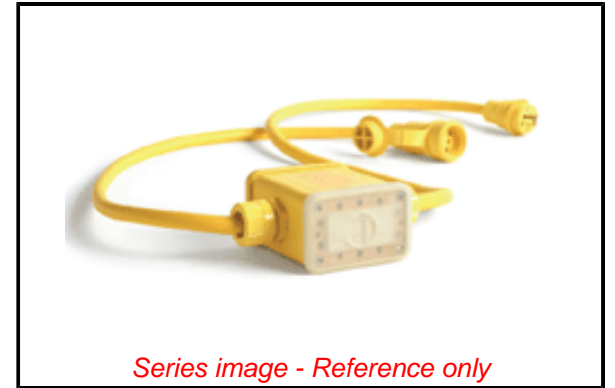

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130137 Series](#)

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**