

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301380081](#)

Status: **Active**

Overview: [Watertite Wet-Location Wiring Solutions](#)

Description: Watertite Multiple Outlet Pendant Box, (2) NEMA 5-20 Duplex with Flip Lids, 4.57m (15.0') Cord Length, 12/3 SOOW Cord, Double Eye Wire Mesh Support Grip

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Literature \(PDF\)](#)

General

Product Family	Power Distribution
Series	130138
Enclosure Rating	NEMA 4
Exclude SD Check	Yes
GFCI Reset	N/A
Mounting Style	Portable
Open Neutral Relay	N/A
Overview	Watertite Wet-Location Wiring Solutions
Product Literature Order No	987650-7737
Product Name	Watertite
Receptacle Type	Duplex
Type	Multiple Outlet Box
UPC	78678840982

Physical


Cord Diameter	15.24mm (.600")
Cord Grip Body Size	F3 3/4"
Cord Length	4.57m (15.0')
Feed-Thru	No
Flip Lid	Yes
Material - Housing	Rubber
Number of Receptacles	2
Packaging Type	Carton

Electrical

Cord Type	12/3 SOOW
Current - Maximum per Contact	20.0A
GFCI	No
Ground Continuity Monitor	No
NEMA Configuration	NEMA 5-20
Voltage - Maximum	N/A

Material Info

Engineering Number	70W33M123
--------------------	-----------

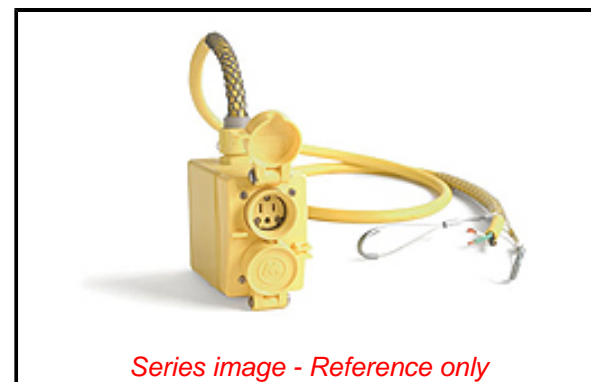

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Relevant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130138](#) Series