

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301500149](#)
Status: **Active**
Overview: [Watertite Wet-Location Wiring Solutions](#)
Description: 20 Amp Watertite Pin and Sleeve Receptacle with Flip Lid, 3 Pole/4 Wire, 250V, Blue

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E145923

General

Product Family Wiring Devices
 Series [130150](#)
 Comments IEC Configuration 309-1/309-2, IEC Configuration 309-1/309-2
 Exclude SD Check Yes
 IP Rating IP67
 NEMA Configuration N/A
 Overview [Watertite Wet-Location Wiring Solutions](#)
 Product Name Watertite
 Receptacle Type Single
 Specialty Pin and Sleeve
 Type Receptacle
 UPC 78678870339

Physical


Flange Yes
 Flip Lid Yes
 Gender Female
 Length 241.30mm (9.500")
 Locking Blade No
 Poles 3-pole/4-wire

Electrical

Cord Type N/A
 Current - Maximum per Contact 20.0A
 GFCI No
 Lighted Connector No
 Voltage - Maximum 250V

Material Info

Engineering Number 420R9

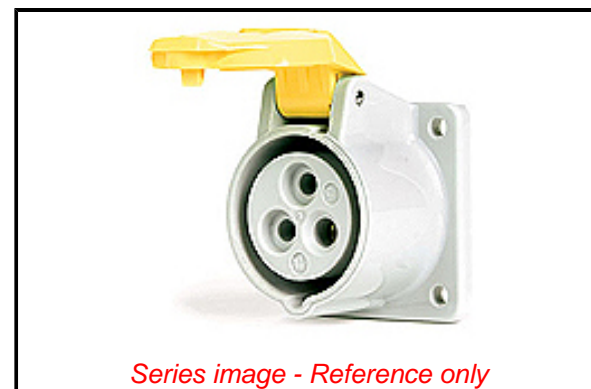

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

[130150 Series](#)