

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301540105](#)  
**Status:** **Active**  
**Overview:** [Heavy-Duty Industrial Wiring Devices](#)  
**Description:** Super-Safeway Molded W Cordset, 2 Pole/3 Wire SJOW Cordset, Cordset Length 0.91m (3.0'), NEMA 5-20, 125V, Inline GFCI

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)      [Product Literature \(PDF\)](#)

**General**

Product Family	Wiring Devices
Series	<a href="#">130154</a>
Exclude SD Check	Yes
IP Rating	N/A
NEMA Configuration	NEMA 5-20
Overview	<a href="#">Heavy-Duty Industrial Wiring Devices</a>
Product Literature Order No	987650-8068
Product Name	Super-Safeway
Receptacle Type	Triple
Specialty	N/A
Type	Molded W Cordset
UPC	78678811794

**Physical**


Flange	No
Flip Lid	No
Gender	Male-Female
Length	0.91m (3.0')
Locking Blade	No
Poles	2-pole/3-wire

**Electrical**

Cord Type	12/3 SJOW
Current - Maximum per Contact	20.0A
GFCI	Yes-In-line
Lighted Connector	No
Voltage - Maximum	125V

**Material Info**

Engineering Number	1433-W-IN
--------------------	-----------

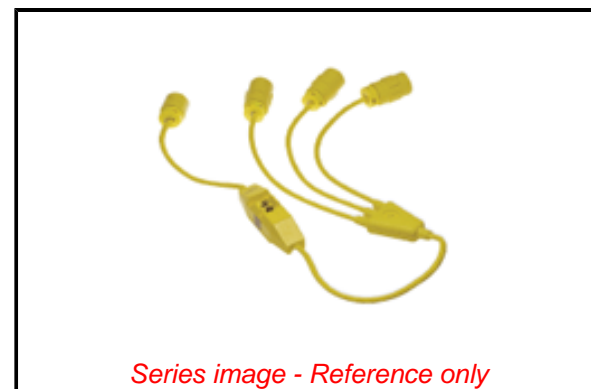

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130154 Series](#)