

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [130010-5001](#)  
**Status:** **Active**  
**Overview:** Brad® Mini-Change® Connectors  
**Description:** Mini-Change® A-Size Double-Ended Cordset, 3 Poles, Male (Straight) to Female (Straight), 16 AWG, TPE Cable, 10.0m (32.81' ) Length

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Industrial Cordsets
Series	<a href="#">130010</a>
Connector End A	Mini-Change®
Connector End B	Mini-Change®
IP Rating	IP67
Overview	<a href="#">Brad® Mini-Change® Connectors</a>
Product Name	Mini-Change®
Protocol	N/A
Region	America
Type	Double Ended
UPC	78172540610

**Physical**

Cable Diameter	10.41mm (.410")
Cable Length	10.0m (32.81' )
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Male-Female
Keyway	Single
LED Indicator	No
Material - Cable Jacket	TPE
Material - Connector Body	PVC
Material - Contact	Copper Alloy
Material - Coupling Nut	Black Epoxy Coated Zinc
Material - Plating Mating	Gold over Nickel
Orientation	Straight
Poles	3
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	16
Wire/Cable Type	TC-ER

**Electrical**


Current - Maximum per Contact	13A
Voltage - Maximum	600V

**Material Info**

Old Part Number	113030K13M100
-----------------	---------------

**Reference - Drawing Numbers**

Sales Drawing	SD-130010-001
---------------	---------------

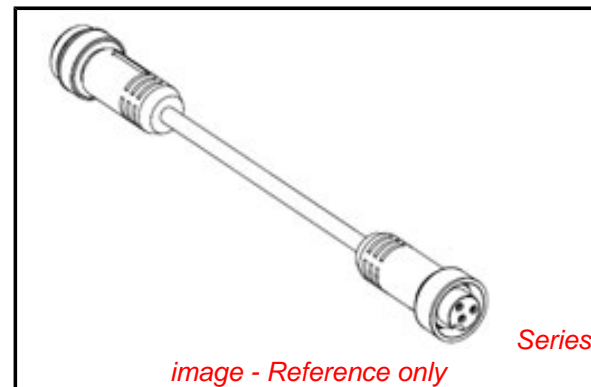

**EU RoHS**

**RoHS Compliant by Exemption**

**REACH SVHC**

Not Reviewed

**Low-Halogen Status**

**Not Reviewed**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

130010Series