

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [130108-0141](#)  
**Status:** **Active**  
**Overview:** [Wide-Area Lighting Products](#)  
**Description:** Super-Safeway™ 27W Fluorescent Machine Light Screw Mount with 18/3 SJTOOW, Overall Cord Length 5.49m (18.0')

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Literature \(PDF\)](#)

**Agency Certification**

CSA LR85374  
 UL E174254

**General**

Product Family Portable Lighting  
 Series [130108](#)  
 NEMA Configuration NEMA 5-15  
 Outlet None  
 Overview [Wide-Area Lighting Products](#)  
 Product Literature Order No 987650-8054  
 Product Name Super-Safeway™  
 Type Wide Area Lamps  
 UPC 78678861308  
 Woodhead Yes

**Physical**


Cord Length - Primary 7.62m (25.0')  
 Cord Length - Secondary N/A  
 Depth 76.20mm (3.000")  
 Duty Industrial  
 Guard Included No  
 Guard Type N/A  
 Height 57.15mm (2.250")  
 Length 552.45mm (21.750")  
 Material - Globe Clear Polycarbonate  
 Material - Guard Nitrile Rubber 80 Shore A  
 Mounting Style Screw-Bracket  
 Packaging Type Carton  
 Socket Construction N/A

**Electrical**

Bulb Type Fluorescent  
 Cord Type - Primary 18/3 SJTOOW  
 Lamp Type PL-L 27/41  
 Lamp Wattage - Maximum 27W  
 Lumens 2000  
 On/Off Switch Yes  
 Voltage (Fixture) - Maximum 120VAC 60 HZ

**Material Info**

Old Part Number 1093-3M

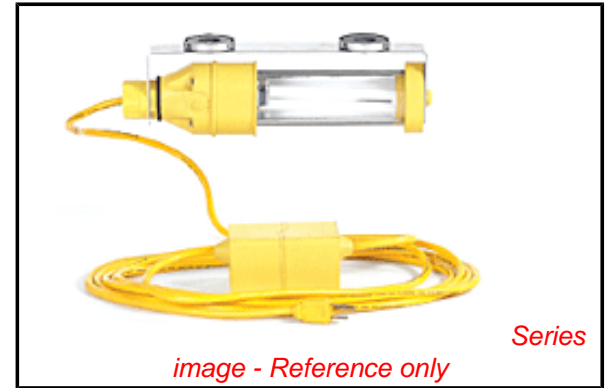

**EU RoHS**

**ELV and RoHS  
 Compliant**  
**REACH SVHC  
 Not Reviewed**  
**Low-Halogen Status  
 Not Reviewed**

**China RoHS**



**Need more information on product  
 environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of  
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

**Search Parts in this Series**

130108Series