

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [130098-0160](#)  
**Status:** **Active**  
**Overview:** [Strain-Relief Cord Grips](#)  
**Description:** MAX-LOC® Strain Relief Cord-Sealing Grip, 1" NPT, 90° Angle Male with O-Ring, Cable Diameter 19.05-22.23mm (.750-.875")

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)      [Product Literature \(PDF\)](#)

**Agency Certification**

CSA	LR32159
UL	E76954

**General**


Product Family	Cable Grips
Series	<a href="#">130098</a>
Eye Type	N/A
NEMA Rating	NEMA 6P
O-Ring	Yes
Overview	<a href="#">Strain-Relief Cord Grips</a>
Product Literature Order No	987650-8064
Product Name	MAX-LOC®
Type	Strain Relief Grip
UPC	78678855572
Use With	MAX-LOC® Lock Nut 1" NPT <a href="#">130099-0145</a>
Woodhead	Yes

**Physical**

Approximate Break Strength	N/A
Bale Length	N/A
Body Style	90° Angle
Cable Diameter	19.05-22.23mm (.750-.875")
Color - Grommet	N/A
Gender	Male
Material - Body	Nylon
Material - Grip	N/A
Mesh Length	N/A
Net Weight	8.610/kg
Number of Holes	1
Thread Size	1" NPT

**Material Info**

Old Part Number	5557W
-----------------	-------

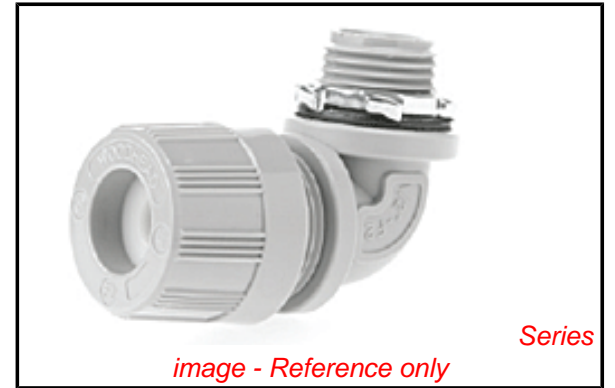

*image - Reference only*

**EU RoHS**

**ELV and RoHS  
Compliant**  
**REACH SVHC  
Not Reviewed**  
**Low-Halogen Status  
Not Reviewed**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

130098Series