

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130064-0178](#)
Status: **Active**
Overview: Brad® Quick-Change® Connectors
Description: Quick-Change® Double-Ended Cordset, 4 Poles, Female (Straight) to Male (Straight), PVC Cable, 10 AWG, PVC Cable, 1.0m (3.28') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Industrial Cordsets
 Series [130064](#)
 Connector End A Quick-Change®
 Connector End B Quick-Change®
 IP Rating IP67
 Overview [Brad® Quick-Change® Connectors](#)
 Product Name Quick-Change®
 Protocol N/A
 Region Europe
 Type Double Ended
 UPC 78678858948

Physical

Cable Diameter 5.08mm (.200")
 Cable Length 1.0m (3.28')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Female-Male
 Keyway Single
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Contact Copper Alloy
 Material - Coupling Nut Anodized Aluminum
 Material - Plating Mating Gold over Nickel
 Orientation Straight
 Poles 4
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 10
 Wire/Cable Type ST00W, TC-ER Direct Burial

Electrical


Current - Maximum per Contact 25.0A
 Voltage - Maximum 600V

Material Info

Old Part Number CC4030A48M010

Reference - Drawing Numbers

Sales Drawing SD-130064-065

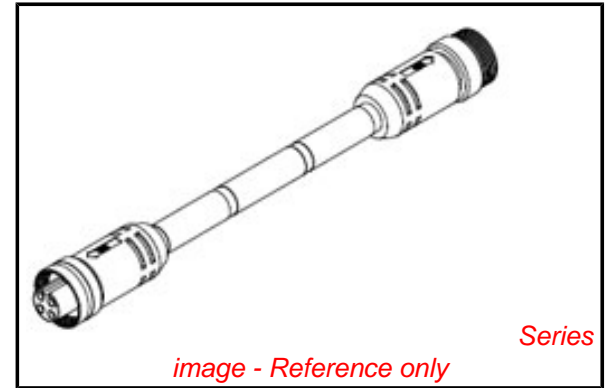

EU RoHS

**ELV and RoHS
Compliant**
REACH SVHC
 Not Reviewed
Low-Halogen Status
Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

130064Series