

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130025-0076](#)
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: Mini-Change® Double-Ended Cordset, 5 Poles, Male (Straight) to Female (Straight), 15 & 18 AWG, DeviceNet* Thick (Trunk) Cable, 6.0m (19.68') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Cordsets
 Series [130025](#)
 Connector End A Mini-Change®
 Connector End B Mini-Change®
 IP Rating IP67
 Overview [Brad® Mini-Change® Connectors](#)
 Product Name DeviceNet* Trunk, Mini-Change®
 Protocol DeviceNet*
 Region Europe
 Type Double Ended
 UPC 78678829919

Physical

Cable Diameter 12.10mm (.480")
 Cable Length 6.0m (19.68')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Male-Female
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Contact Copper Alloy
 Material - Coupling Nut Die-Cast Zinc
 Material - Plating Mating Gold over Nickel
 Orientation Straight
 Poles 5
 Temperature Range - Operating -20°C to +80°C
 Wire Size AWG 15, 18
 Wire/Cable Type N/A

Electrical

Current - Maximum per Contact 4.0A
 Voltage - Maximum 300V AC/DC

Material Info

Old Part Number DN11A-M060

*DeviceNet is a trademark of the ODVA

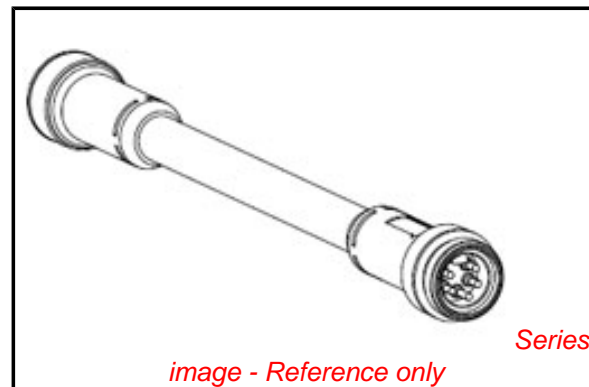


image - Reference only

EU RoHS

RoHS Compliant by Exemption
REACH SVHC
 Not Reviewed
Low-Halogen Status
 Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[130025Series](#)