

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [130058-0059](#)  
**Status:** **Active**  
**Overview:** Brad® Ethernet Solutions  
**Description:** RJ-LNXX RJ45 Female to RJ45 Female Adaptor, Panel Mount Pass Thru

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Field Attachable / Accessories
Series	<a href="#">130058</a>
IP Rating	IP67
Overview	<a href="#">Brad® Ethernet Solutions</a>
Product Name	RJ-Lnxx®
Type	Threaded Interconnect
UPC	78678856747

**Physical**

Cable Diameter	N/A
Coupling Type	External Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Female
Keyway	N/A
Material - Connector Body	Delrin
Material - Contact	N/A
Material - Coupling Nut	Nylon
Material - Plating Mating	n/a
Net Weight	95.480/g
Orientation	Straight
Poles	N/A
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	N/A

**Electrical**


Current - Maximum per Contact	1.5A
Voltage - Maximum	30V DC

**Material Info**

Old Part Number	RJBG17946
-----------------	-----------

**Reference - Drawing Numbers**

Sales Drawing	SD-130058-007
---------------	---------------

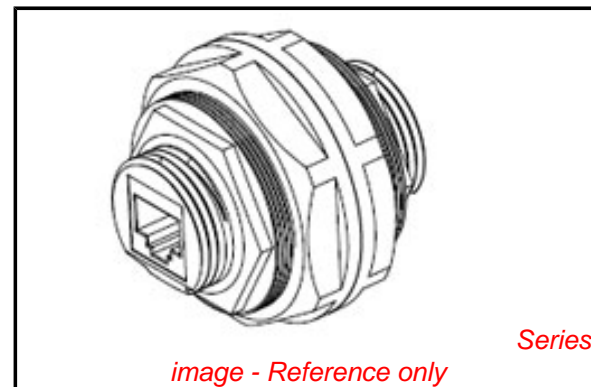

**EU RoHS**

**ELV and RoHS  
Compliant**  
**REACH SVHC**  
 Not Reviewed  
**Low-Halogen Status**  
 Not Reviewed

**China RoHS**



**Need more information on product  
environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of  
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

**Search Parts in this Series**

130058Series