

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [130011-0010](#)
Status: **Active**
Overview: Brad® Mini-Change® Connectors
Description: Mini-Change® B-Size Double-Ended Cordset, 6 Poles, Male (Straight) to Female (Straight), 16 AWG, PVC Cable, 1.83m (6.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Cordsets
 Series [130011](#)
 Connector End A Mini-Change®
 Connector End B Mini-Change®
 IP Rating IP67
 Overview [Brad® Mini-Change® Connectors](#)
 Product Name Mini-Change®
 Protocol N/A
 Region America
 Type Double Ended
 UPC 78678844040

Physical

Cable Diameter 13.72mm (.540")
 Cable Length 1.83m (6.0')
 Color - Cable Jacket Yellow
 Coupling Style Threaded
 Gender Male-Female
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Contact Brass
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold
 Net Weight 298.870/g
 Orientation Straight
 Poles 6
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 16
 Wire/Cable Type ST00W

Electrical


Current - Maximum per Contact 8A
 Voltage - Maximum 600V

Material Info

Old Part Number 226020A01F060

Reference - Drawing Numbers

Sales Drawing SD-130011-001

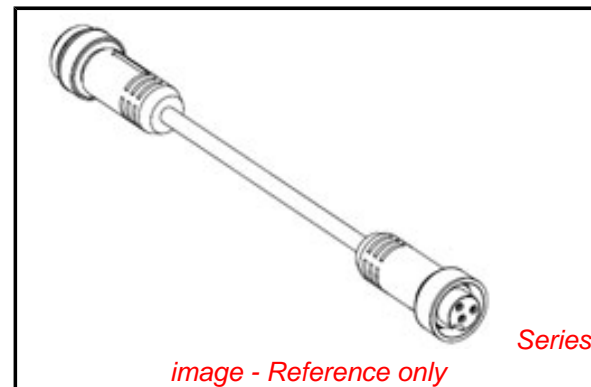

EU RoHS

RoHS Compliant by Exemption
REACH SVHC
 Not Reviewed
Low-Halogen Status
 Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

130011Series

This document was generated on 10/02/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION