


164271001 (OD6038-24MBVXC)



DC Fan - 24V
60x60x38mm (2.36"x1.49")

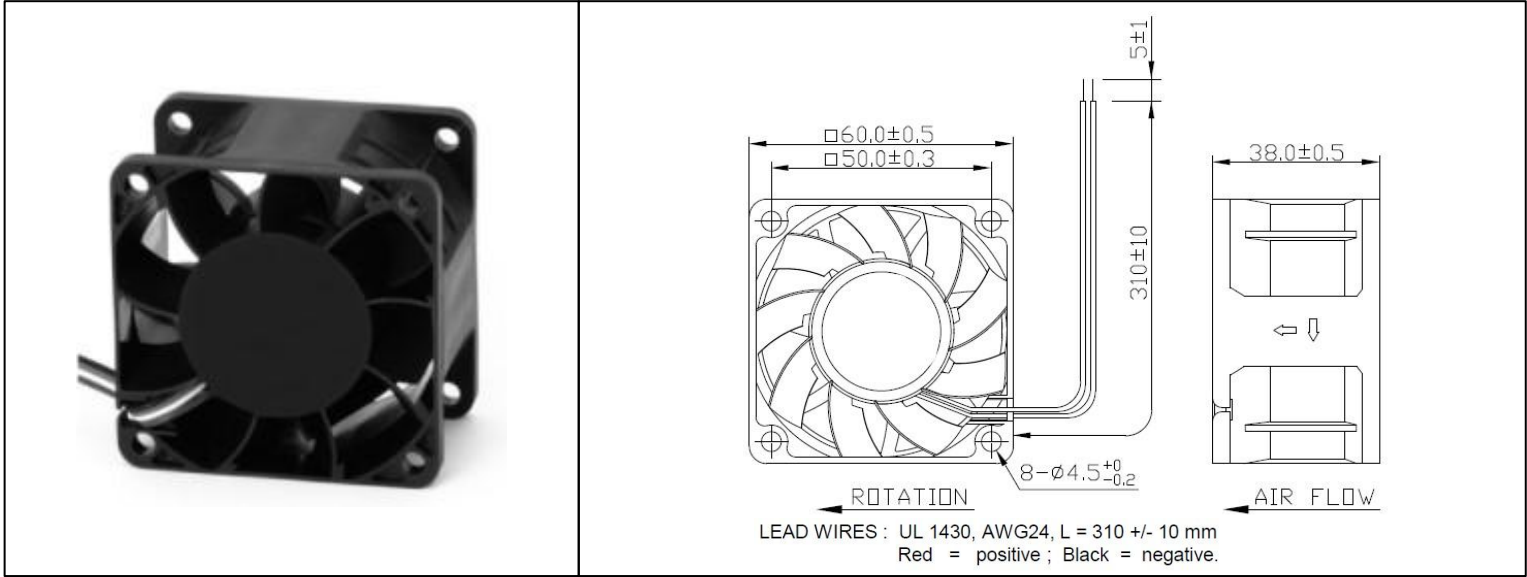

Frame	PBT, UL94 V-0 Plastic	<u>Operating Temperature</u> -10°C ~ +70°C <u>Storage Temperature</u> -40°C ~ +80°C <u>Life Expectancy</u> 70,000 Hours (L10 at 40°C) Weight: 0.24 lbs.	
Impeller	PBT, UL94 V-0 Plastic		
Connection	2x Wire Leads, 24 AWG		
Motor	Brushless DC, Auto Cutoff, Auto Restart, Electronically Protected, Polarity Protected		
Bearing System	Ball Bearings		
Dielectric Strength	500VDC/min, <1mA		
Insulation Resistance	≥10M Ohm @ 500 VDC		

Part Number	164271001 (OD6038-24MBVXC)
Rated Voltage (Volts DC)	24
Voltage Range (Volts DC)	21.6 ~ 26.4
Input Power (Watts)	10.32
Rated Current (Amps)	0.43
Rated Speed (RPM)	8000
Max Airflow (CFM)	45.8
Noise Level (dBA)	58
Max Static Pressure ("H ₂ O)	0.97