


Synthetic cable glands Syntec® with lamellar technology

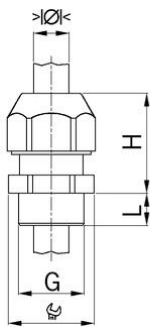

Entry thread Pg

Type approval: SYNTEC

- Light grey RAL 7035
- One-piece sealing ring

Order number:	1555.07.06
E-No:	121754028
EAN:	7611614077765
Material	Polyamide PA 6
Properties	halogen-free, black UV resistant (tested according to EN ISO 4892-2)
Sealing ring	CR (neoprene)
Operation temperature	-30°C / +100°C
Protection class	IP 68
NEMA Type rating	4X
Entry thread	Pg 7
Clamping range min.	2.5 mm
Clamping range max.	6.5 mm
Wrench size	15 mm
Dimension H	21 mm
Thread length L	8 mm
UL - clamping range	5.0-6.5 mm
Dispatch	100