


Synthetic cable glands Syntec® with lamellar technology

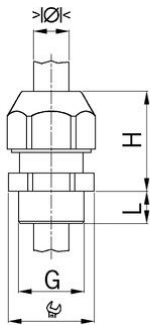

Entry thread Pg

Type approval: SYNTEC

- Light grey RAL 7035
- One-piece sealing ring

Order number:	1555.21.18
E-No:	121754528
EAN:	7611614077857
Material	Polyamide PA 6
Properties	halogen-free, black UV resistant (tested according to EN ISO 4892-2)
Sealing ring	CR (neoprene)
Operation temperature	-30°C / +100°C
Protection class	IP 68
NEMA Type rating	4X
Entry thread	Pg 21
Clamping range min.	11.0 mm
Clamping range max.	18.0 mm
Wrench size	33 mm
Dimension H	35 mm
Thread length L	11 mm
UL - clamping range	12.0-18.0 mm
Dispatch	25