

Datasheet

Art.No. 70.320.2428.0

Bottom BAS GUT GA 24 A

revos BASIC 500V size 24 open-bottom base, double locking lever



Art.No.	70.320.2428.0
EAN	4015573220119
Order unit	1 pieces

Approvals



Technical data

General

Housing material	Aluminium
Colour	Grey
Surface	With powder coating
Degree of protection (IP)	IP54
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

Model

DIN-size	24
Model	Equipment mounted (feed-through)
Locking mechanism	Double locking levers
Cable entry	None
Type of cable	None
With cable screw gland	No
Hinged lid	No
EMC-version	No

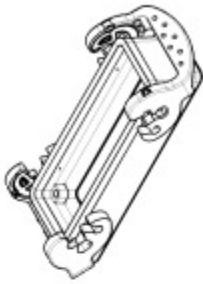
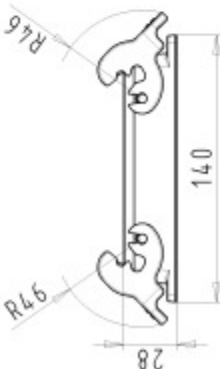
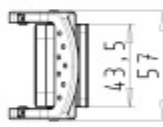

Classification

ECLASS 8.1	27440202: Housing for industrial connectors
ETIM 5.0	EC000437: Housing for industrial connectors
ETIM 4.0	EC000437: Housing for industrial connectors

ETIM 3.0

EC000437: Housing for industry plug connectors

Drawings

70.320.2428.0	BAS 60T GA 24 A
Bestellnummer / Order number	Typ / Type
Weitere Daten, siehe KATALOG oder eCatalog - www.wieland-electric.com Additional data see CATALOG or eCatalog - www.shop.wieland-electric.com	
1. Beschreibung, siehe auch in den Unterlagen des Herstellers (englisch / deutsch / französisch) / Description, see also in the documents of the manufacturer (English / German / French) 2. Zeichnung, siehe auch in den Unterlagen des Herstellers (englisch / deutsch / französisch) / Drawing, see also in the documents of the manufacturer (English / German / French) 3. Verpackung, siehe auch in den Unterlagen des Herstellers (englisch / deutsch / französisch) / Packaging, see also in the documents of the manufacturer (English / German / French)	
Artikelnummer / Part number 70.320.2428.0 13K	Zeichnung Nr. / Drawing No. -
GEHAUSEUNTERTEIL Baugröße 24, 414mm OPEN HOUSING size 24	

Bohrbild / Cut out

Die Abmessungen sind in mm angegeben.
 Die Abmessungen sind in mm angegeben.
 Die Abmessungen sind in mm angegeben.
 Die Abmessungen sind in mm angegeben.
 Die Abmessungen sind in mm angegeben.