




Kellems® Wire Management Products
Hubbell Juniors® Miniature Connectors



Hubbell Juniors are a miniature liquidtight version of the full-sized Hubbell cord connectors. They feature the same GOTCHA® ring technology and neoprene bushings. They also come with or without a nylon spiral for arc-of-bend control and longer cord life. They are available in ¼", ⅜", and ½" N.P.T. sizes in both gray and black.

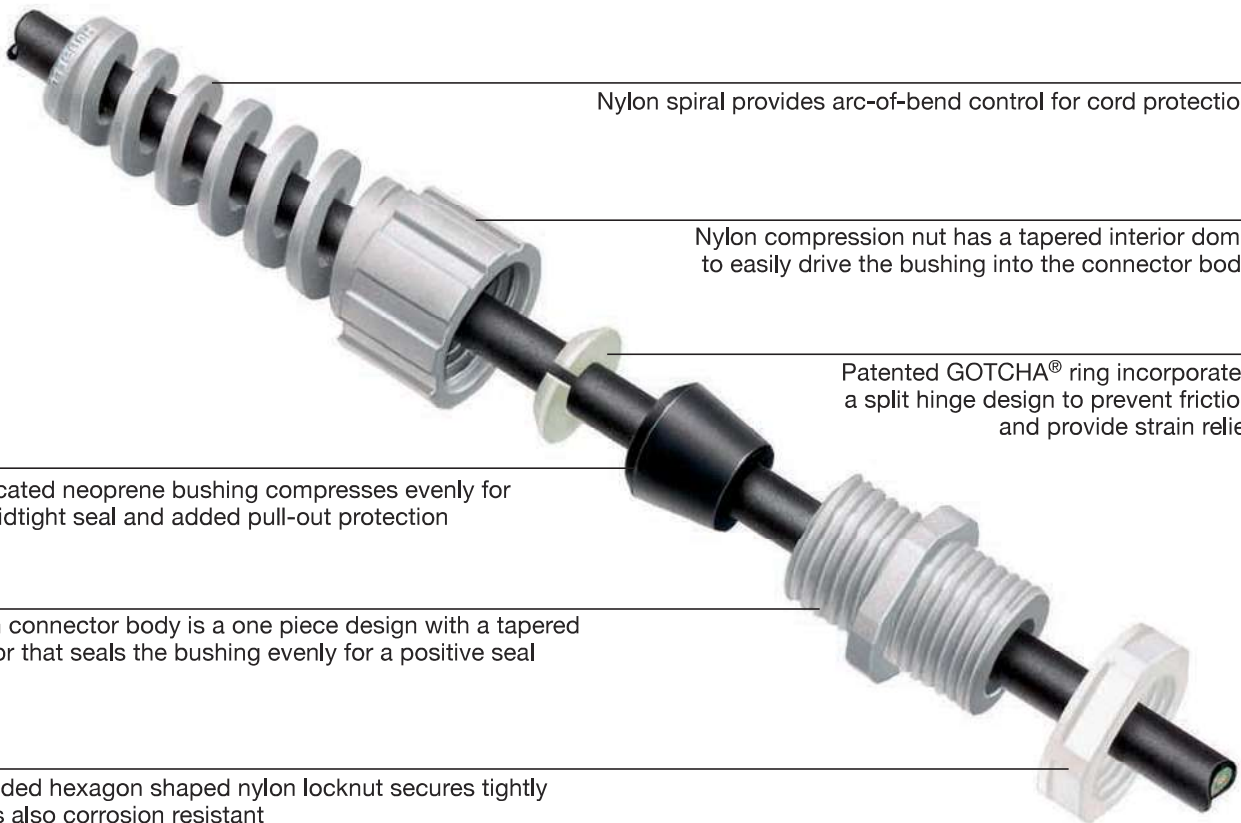

Nylon spiral provides arc-of-bend control for cord protection

Nylon compression nut has a tapered interior dome to easily drive the bushing into the connector body

Patented GOTCHA® ring incorporates a split hinge design to prevent friction and provide strain relief

Lubricated neoprene bushing compresses evenly for a liquidtight seal and added pull-out protection

Nylon connector body is a one piece design with a tapered interior that seals the bushing evenly for a positive seal

Threaded hexagon shaped nylon locknut secures tightly and is also corrosion resistant

Kellems® Wire Management Products

Hubbell Juniors® Miniature Nylon Cord Connectors



Miniature Nylon Cord Connector

N.P.T. Hub Size	Cord Diameter Range		Gray	Black
	Inches	(mm)		
1/4	.08"-.14"	(1.9-3.4)	HJ1001GPK25	HJ1001BPK25
	.14"-.20"	(3.4-5.1)	HJ1002GPK25	HJ1002BPK25
	.20"-.27"	(5.1-6.7)	HJ1003GPK25	HJ1003BPK25
3/8	.15"-.21"	(3.7-5.3)	HJ1004GPK25	HJ1004BPK25
	.21"-.28"	(5.3-7.0)	HJ1005GPK25	HJ1005BPK25
	.28"-.34"	(7.0-8.6)	HJ1006GPK25	HJ1006BPK25
1/2	.06"-.13"	(1.6-3.2)	HJ1055GPK25	HJ1055BPK25
	.13"-.19"	(3.2-4.7)	HJ1056GPK25	HJ1056BPK25
	.19"-.25"	(4.7-6.3)	HJ1057GPK25	HJ1057BPK25
	.25"-.31"	(6.3-7.9)	HJ1058GPK25	HJ1058BPK25
	.31"-.38"	(7.9-9.5)	HJ1059GPK25	HJ1059BPK25
	.38"-.44"	(9.5-11.1)	HJ1060GPK25	HJ1060BPK25



Gray Cord Connector



Black Cord Connector

Miniature Nylon Cord Connector with Spiral

N.P.T. Hub Size	Cord Diameter Range		Gray	Black
	Inches	(mm)		
1/4	.08"-.14"	(1.9-3.4)	HJ1010GPK25	HJ1010BPK25
	.14"-.20"	(3.4-5.1)	HJ1011GPK25	HJ1011BPK25
	.20"-.27"	(5.1-6.7)	HJ1012GPK25	HJ1012BPK25
3/8	.15"-.21"	(3.7-5.3)	HJ1013GPK25	HJ1013BPK25
	.21"-.28"	(5.3-7.0)	HJ1014GPK25	HJ1014BPK25
	.28"-.34"	(7.0-8.6)	HJ1015GPK25	HJ1015BPK25
1/2	.13"-.19"	(3.2-4.7)	HJ1038GPK25	HJ1038BPK25
	.19"-.25"	(4.7-6.3)	HJ1039GPK25	HJ1039BPK25
	.25"-.31"	(6.3-7.9)	HJ1040GPK25	HJ1040BPK25
	.31"-.38"	(7.9-9.5)	HJ1041GPK25	HJ1041BPK25
	.38"-.44"	(9.5-11.1)	HJ1042GPK25	HJ1042BPK25
3/4	.25"-.49"	(6.4-12.3)	HJ1043GPK25*	HJ1043BPK25*
	.45"-.71"	(11.4-18.0)	HJ1044GPK25*	HJ1044BPK25*



Gray Cord Connector with Spiral



Black Cord Connector with Spiral

Note: * Locknuts sold separately. See page T-89.

Miniature Nylon Snap-In Cord Connector with Spiral

Cord Diameter Range	For Chassis Thickness	Gray	Black	
				Inches
.22"-.27"	(5.6-6.9)	.10" (2.5) Max	HS1001GPK25	HS1001BPK25
.28"-.32"	(7.1-8.1)	.10" (2.5) Max	HS1002GPK25	HS1002BPK25
.30"-.36"	(7.6-9.1)	.13" (3.2) Max	HS1003GPK25	HS1003BPK25
.32"-.43"	(8.1-10.9)	.13" (3.2) Max	HS1004GPK25	HS1004BPK25

Note: Catalog numbers above with "PK25" suffix, i.e. HJ1001GPK25, are bulk packed 25 per carton. See pages T-102 and T-103 for additional technical data and dimensional drawings.



Gray Snap-In Cord Connector



Black Snap-In Cord Connector