




WIRE TERMINATION

WWW.IDEALIND.COM • 1-800-435-0705 CUSTOMER ASSISTANCE

Vinyl Insulated Ring Terminal Dimensions

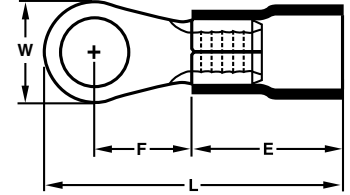

Wire Range (AWG)	Wire Range (mm ²)	Stud Size (in.)	Stud Size (mm)	Max. Wire Ins. Dia. (in.)	Max Wire Ins. Dia. (mm)	Dimensions (in.)				Dimensions (mm)				Cat. No.
						L	W	E	F	L	W	E	F	
22-18	0.5 - 1.0	6	3.7	.157	4.0	.764	.260	.394	.248	19.4	6.6	10.0	6.3	83-2121
		8	4.3			.819	.315	.394	.276	20.8	8.0	10.0	7.0	83-2131
		10	5.3			.819	.315	.394	.276	20.8	8.0	10.0	7.0	83-2141
		1/4	6.4			1.055	.457	.394	.433	26.8	11.6	10.0	11.0	83-2151
16-14	1.5 - 2.5	6	3.7	.177	4.5	.764	.260	.394	.248	19.4	6.6	10.0	6.3	83-2221
		8	4.3			.858	.335	.394	.307	21.8	8.5	10.0	7.8	83-2231
		10	5.3			.858	.374	.394	.287	21.8	9.5	10.0	7.3	83-2241 84-2241
		1/4	6.4			1.055	.472	.394	.433	26.8	12.0	10.0	11.0	83-2251
12-10	4.0 - 6.0	8	4.3	.248	6.3	1.047	.374	.512	.358	26.6	9.5	13.0	9.1	83-2331
		10	5.3			1.047	.374	.512	.358	26.6	9.5	13.0	9.1	83-2341 84-2341
		1/4	6.4			1.167	.472	.512	.413	29.5	12.0	13.0	10.5	83-2351
		5/16	8.4			1.339	.591	.512	.531	34.0	15.0	13.0	13.5	83-2361
		3/8	10.5			1.339	.591	.512	.531	34.0	15.0	13.0	13.5	83-2371

75°C/600 Volts max.

