

McGILL 0871, 0881 Series

Snap-Cap Style Rocker Switches




The McGill 0871, 0881 series feature interchangeable rocker caps for applications where a variety of rocker combinations are required. Available with a variety of circuits, terminations and lamp configurations, the 0871 or 0881 series offer the added flexibility of snap-on colored caps in curved, half-serrated or full-serrated configurations.

Specifications

- UL recognized, CSA certified
 - 15A, 277VAC
 - 3/4 HP, 125-277VAC
- VDE approval available
- 125V and 250VAC neon lamps available
- 14V and 28VDC incandescent lamps available

Panel Opening

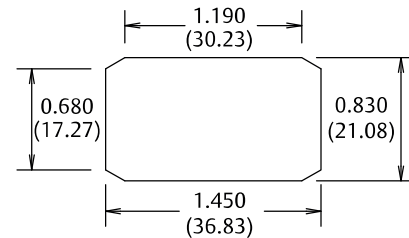


Panel Thickness

.040 (1.02) – .187 (4.75)

Construction


- .250 x .032 spade terminals
- .187 spade terminals, screw terminals, solder terminals and 16-gauge wire leads are also available. Consult factory for other circuits, colors or custom designs.

Curved Cap Version

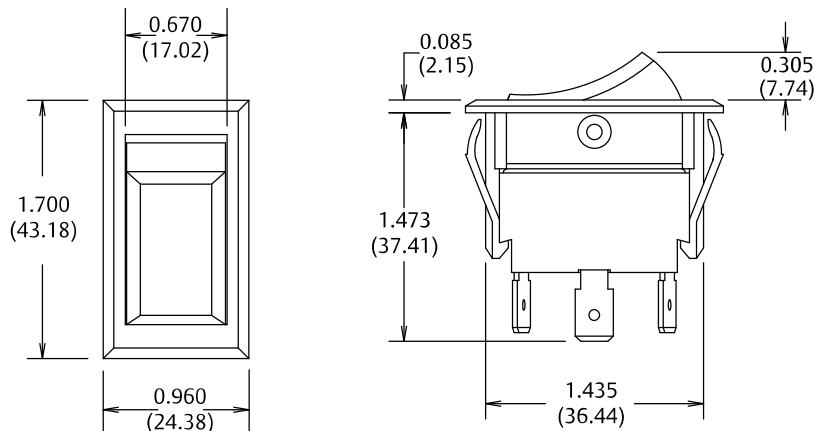

Approximate dimensions in inches and (millimeters).

Serrated Cap Version

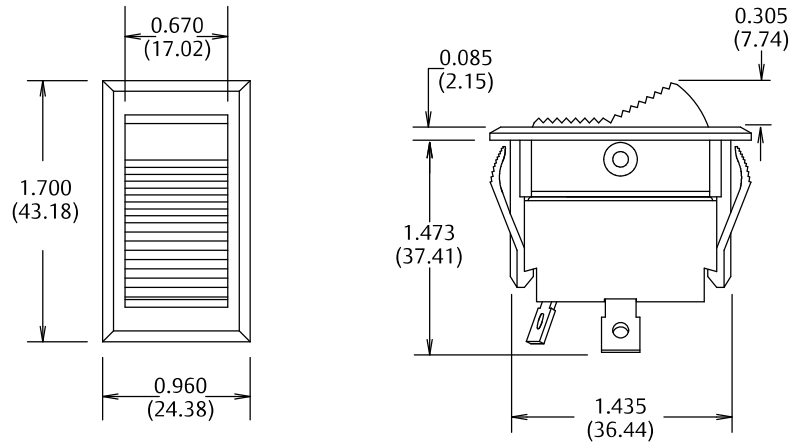

0871 and 0881 Snap-Cap Style Rocker Switches Black Bezel, without Snap-On Colored Caps*

Circuit Arrangement			Lights	SINGLE POLE		DOUBLE POLE	
A	B	C		Poles	Cat. No.	Poles	Cat. No.
on	—	off	1	SPST	0871-1601	DPST	0881-1601
on	off	on	2	SPDT	0871-2602	DPDT	0881-2602
on	—	on	2	SPDT	0871-2603	DPDT	0881-2603
(on)	—	off	1	SPST	0871-1604	DPST	0881-1604
(on)	off	(on)	2	SPDT	0871-2605	DPDT	0881-2605
(on)	off	on	2	SPDT	0871-2606	DPDT	0881-2606
on	—	(off)	1	SPST	0871-1607	DPST	0881-1607
(on)	—	on	2	SPDT	0871-2608	DPDT	0881-2608

() Momentary

* To order unlighted switch (no rocker cap), change the 5th digit of the catalog number to "0" (example: 0861-06XX).

Snap-On Colored Caps

Color	Full Cap Serrated	1/2 Cap Serrated	Curved Full Satin Clear Cap
white	0871-0000	0871-0010	0871-0020
clear	0871-0100	0871-0110	0871-0120
amber	0871-0200	0871-0210	0871-0220
red	0871-0300	0871-0310	0871-0320
green*	0871-0400	0871-0410	0871-0420
blue*	0871-0500	0871-0510	0871-0520
black	0871-0800	0871-1810	—

* Green and blue caps require special lamps; consult factory.