

SWITCHES APPLIANCE & SPECIALTY

FEED THRU CORD SWITCH

SPECIFICATIONS:

Current Rating:	6A @ 125V AC, 3A @ 250V AC
Initial Contact Resistance:	DC 2.5V-1A, 20 Meg ohm (Min.)
Insulation Resistance:	500V DC 100 Meg ohm (Min.)
Dielectric Strength:	1500V AC for 1 minute
Contact Material:	Brass
Terminal Material:	Spring Brass
Terminal Type:	Insulation Piercing

Part No.	Type	Action			Actuator
30-10098	SPST	ON	-	OFF	Round Plastic Dial



HI-LO INLINE DIMMER SWITCH

SPECIFICATIONS:

Current Rating:	6A @ 125V AC, 3A @ 250V AC
Initial Contact Resistance:	DC 2.5V-1A, 20 Meg ohm (Min.)
Insulation Resistance:	500V DC 100 Meg ohm (Min.)
Dielectric Strength:	1500V AC for 1 minute
Contact Material:	Brass
Terminal Material:	Spring Brass
Terminal Type:	Insulation Piercing

Part No.	Type	Action			Actuator
30-10196	SPDT	ON	ON	OFF	Round Plastic Dial




FEED THRU CORD SWITCH

SPECIFICATIONS:

Current Rating:	10A @125V AC
Dielectric Strength:	300 Volt
Terminal Material:	Brass
Terminal Type:	Screw
Wire Type:	Flat or round cords Flat: 18/2 & 16/2, SPT-1, SPT-2, HPN Round: 18/2 type SVT, up to 9/32" O.D.

Part No.	Type	Action			Actuator
30-9851	SPST	ON	-	OFF	Black W/White Legend

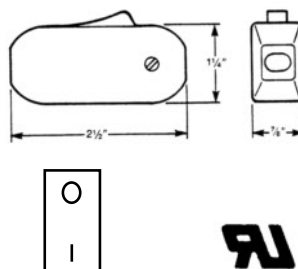

CORDED INLINE DIMMER SWITCH

SPECIFICATIONS:

Current Rating:	1.2A @ 125V AC
Initial Contact Resistance:	DC 2.5V-1A, 20 Meg ohm (Min.)
Insulation Resistance:	500V DC 100 Meg ohm (Min.)
Dielectric Strength:	1500V AC for 1 minute
Contact Material:	Brass
Terminal Material:	UL SPT-1 18AWG 2 Cond. Wire, Stripped
Terminal Type:	120V AC Plug/Stripped Ends

Part No.	Type	Action			Actuator
30-10192	SPST	ON	-	OFF	Roller Ball



(6 ft. Overall Length)